

F1A-TNRNR-M815-C4



FSJ1-50A SureFlex® Jumper with interface types N Male Right Angle and N Male Right Angle, 0.815 m

Product Classification

Product Series FSJ1-50A
Product Type SureFlex® standard

General Specifications

Body Style, Connector A Right angle
Body Style, Connector B Right angle
Interface, Connector A N Male
Interface, Connector B N Male
Length 0.815 m | 2.674 ft
Nominal Size 1/4 in
Orientation 0°
Specification Sheet Revision Level A


Electrical Specifications

3rd Order IMD -80.00 dBm
DTF, Connector A -29.50 dB
DTF, Connector B -29.50 dB

Environmental Specifications

Immersion Test Method Meets IEC 60529:2001, IP68 in mated condition

Jumper Assembly Sample Label

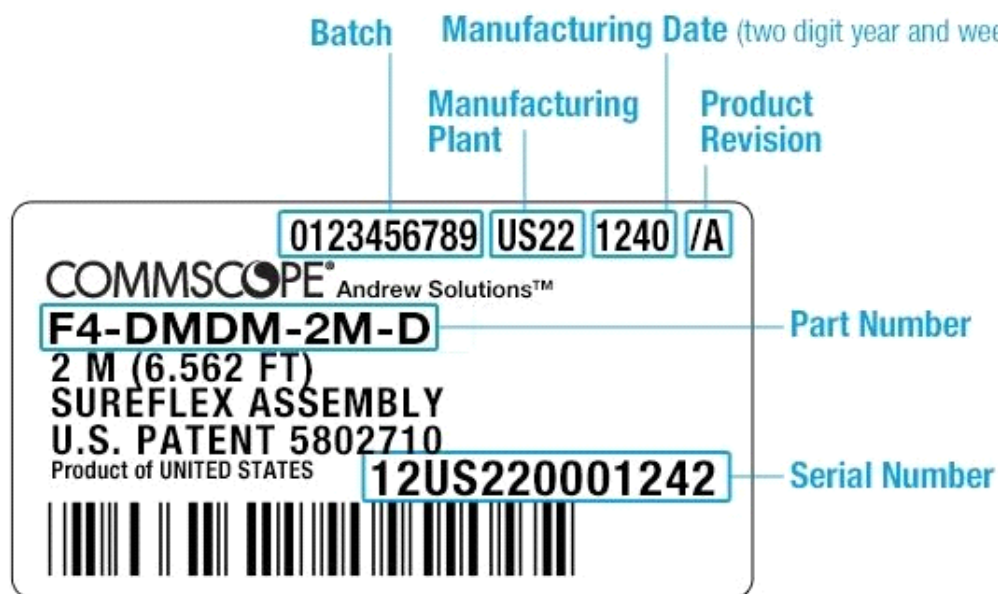

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
400–2200 MHz	1.20	20.83

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



Included Products

- FSJ1-50A — FSJ1-50A, HELIAX® Superflexible Low Density Foam Coaxial Cable, corrugated copper, 1/4 in, black PE jacket
- FSJ1RK-50B — FSJ1-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/4 in, black non-halogenated, fire retardant polyolefin jacket, B2ca s1a dO a1 Compliant
- 35422-75 — Heat Treated FSJ1RK-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/4 in, black non-halogenated, fire retardant polyolefin jacket
- 35422-33 — Heat Treated FSJ1-50A, HELIAX® Superflexible Low Density Foam Coaxial Cable, corrugated copper, 1/4 in, black PE Jacket