



OWB Fiber Optic Wall Mount Fiber Box, 2 SC/UPC adapters, fusing splice, 8 fuse splice protectors, no splitters

- Compact sized with multiple cable entry point options
- Used as a premises connection device in FTTH networks
- Easy access via the combined hinge + latch design
- High sealing rate, UV resistant and UL compliant
- Slack storage (3 mtr) for drop- and premise connection cable

## Product Classification

<b>Product Type</b>	Fiber wall box
<b>Product Series</b>	OWB
<b>Regional Availability</b>	North America


## General Specifications

<b>Application</b>	For cables with outer diameter 3 x 5.4 mm: 1 on top + 1 on bottom   For cables with outer diameter up to 10 mm: each on both sides   For cables with outer diameter up to 5 mm: 1 on rear + 4 on bottom
<b>Enclosure Color</b>	Gray
<b>Functionality</b>	Patching   Splicing
<b>Includes</b>	Grommets
<b>Interface Feature, input</b>	APC
<b>Interface, input</b>	SC
<b>Package, quantity</b>	1
<b>Packaging Type</b>	Box   Carton
<b>Port Capacity, maximum</b>	4
<b>Port, quantity</b>	2
<b>Splicing Capacity, maximum</b>	8

## Dimensions

<b>Depth</b>	71.88 mm   2.83 in
<b>Height</b>	209.80 mm   8.26 in
<b>Width</b>	173.74 mm   6.84 in

## Dimension Drawing

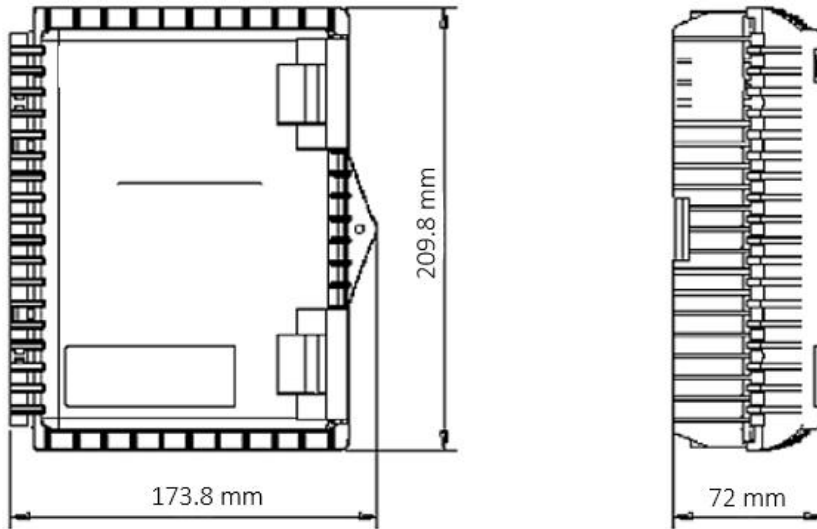

**Dimension Drawing**

Used as an image placeholder

## Mechanical Specifications

<b>Access</b>	Front
<b>Enclosure Material Type</b>	LSZH thermoplastic
<b>Front Cover Type</b>	Hinged with latches
<b>Lock Type</b>	Ski latch and screw
<b>Mount Type</b>	Wall

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Insertion Loss, Terminal Connector, maximum</b>	0.10 dB

## Environmental Specifications

<b>Environmental Space</b>	Outdoor
<b>Flammability Rating</b>	UL 94 V-0
<b>Installation Temperature</b>	-5 °C to +45 °C (+23 °F to +113 °F)
<b>Qualification Standard</b>	IEC 60529, IP65
<b>Storage Temperature</b>	-40 °C to +70 °C (-40 °F to +158 °F)

## Regulatory Compliance/Certifications

**Agency**  
RoHS 2011/65/EU

**Classification**  
Compliant

