


CWFMT-2LLBEOCN1-D

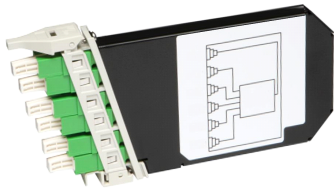

FMT MicroVAM Fiber Optic Module, CWDM, 4 channels, mux/demux, SC/APC, starting wavelength 1531 nm

Product Classification

Product Type	CWDM module
Product Series	FMT
Regional Availability	North America

General Specifications

Distribution Type	4-channel CWDM
Interface, input	SC
Interface, output	SC
Application	For use with FMT panels For use with NGF frames
Circuits, quantity	1
Functionality	Demultiplexing Multiplexing
Interface Feature, input	APC
Interface Feature, output	APC
Multiplexers, quantity	1
Package, quantity	1

Dimensions

Depth	177.80 mm 7.00 in
Height	71.88 mm 2.83 in
Width	17.27 mm 0.68 in

Mechanical Specifications

Device Type	Micro VAM
Access	Front

Optical Specifications

Starting Wavelength	1531.00 nm
----------------------------	------------

Regulatory Compliance/Certifications

Agency	RoHS 2011/65/EU
---------------	-----------------

Classification	Compliant
-----------------------	-----------

