

F1-UMMU-3



FSJ1-50A Jumper with interface types UHF Male and UHF Male, 0.91 m

Product Classification

Product Series FSJ1-50A
Product Type SureFlex® standard

General Specifications

Body Style, Connector A Straight
Body Style, Connector B Straight
Interface, Connector A UHF Male
Interface, Connector B UHF Male
Length 0.910 m | 2.986 ft
Nominal Size 1/4 in
Specification Sheet Revision Level A


Electrical Specifications

DTF, Connector A -10.00 dB
DTF, Connector B -10.00 dB

Environmental Specifications

Immersion Test Method Meets IEC 60529:2001, IP68 in mated condition

Jumper Assembly Sample Label

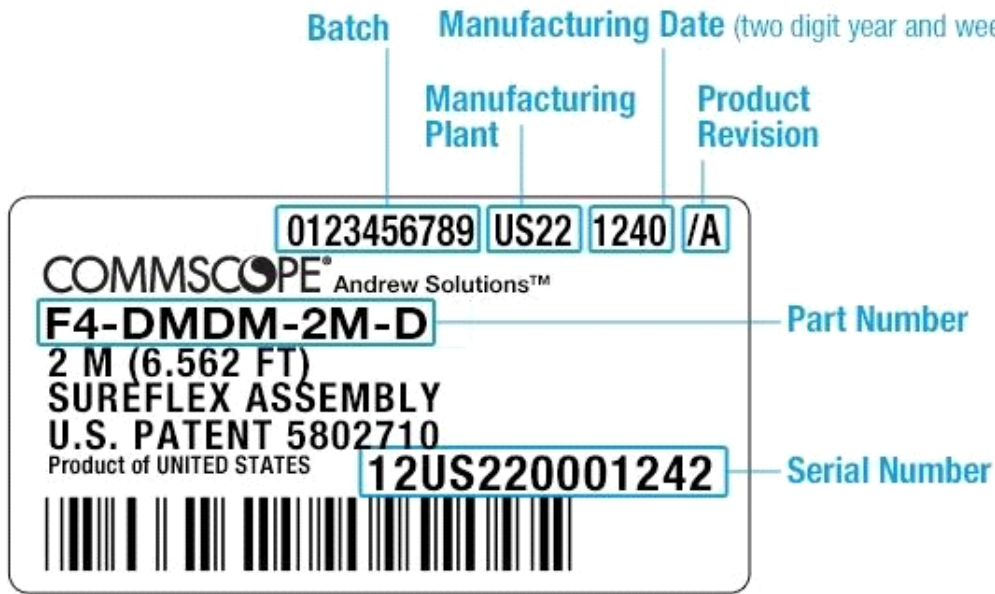

Regulatory Compliance/Certifications

Agency

RoHS 2011/65/EU

ISO 9001:2015

China RoHS SJ/T 11364-2014

Classification

Compliant by Exemption

Designed, manufactured and/or distributed under this quality management system

Above Maximum Concentration Value (MCV)



Included Products

FSJ1-50A — FSJ1-50A, HELIAX® Superflexible Low Density Foam Coaxial Cable, corrugated copper, 1/4 in, black PE jacket

F1MU — Mini UHF Male for 1/4 in FSJ1-50A cable

FSJ1RK-50B — FSJ1-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/4 in, black non-halogenated, fire retardant polyolefin jacket, B2ca s1a dO a1 Compliant

35422-75 — Heat Treated FSJ1RK-50B, HELIAX® Superflexible Foam Coaxial Cable, corrugated copper, 1/4 in, black non-halogenated, fire retardant polyolefin jacket

35422-33 — Heat Treated FSJ1-50A, HELIAX® Superflexible Low Density Foam Coaxial Cable, corrugated copper, 1/4 in, black PE Jacket