



31510-21 SureFlex® Jumper with interface types N Male and N Male,
18.902 m

Product Classification

Product Series LDF4-50A
Product Type SureFlex® standard

General Specifications

Body Style, Connector A Straight
Body Style, Connector B Straight
Interface, Connector A N Male
Interface, Connector B N Male
Length 18.902 m | 62.014 ft
Nominal Size 1/2 in
Specification Sheet Revision Level A


Electrical Specifications

DTF, Connector A -32.00 dB
DTF, Connector B -32.00 dB

Environmental Specifications

Immersion Test Method Meets IEC 60529:2001, IP68 in mated condition

Jumper Assembly Sample Label

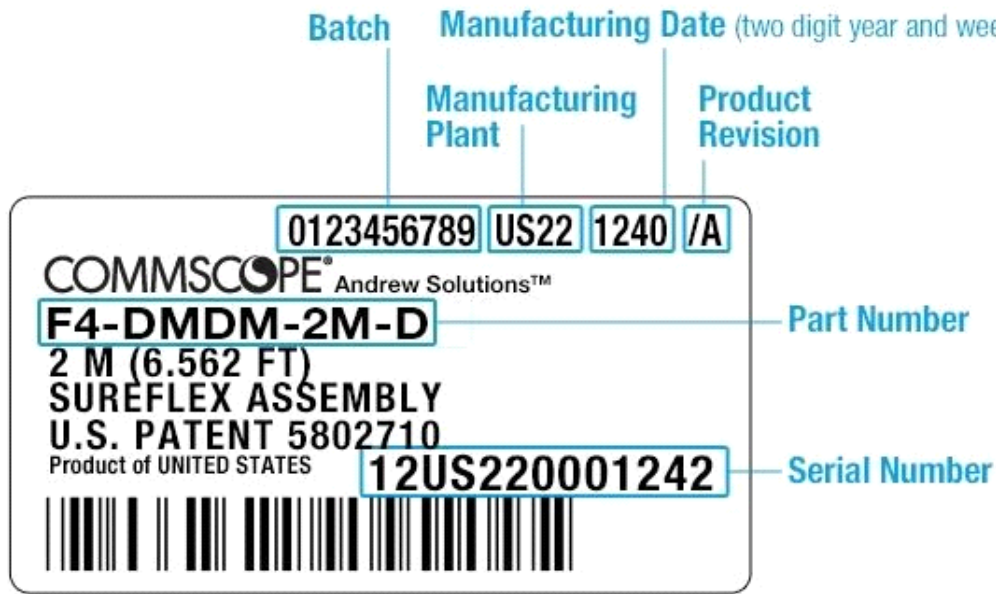

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
420–450 MHz	1.15	23.10

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2011/65/EU	Compliant by Exemption
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
China RoHS SJ/T 11364-2014	Above Maximum Concentration Value (MCV)

