



AMPINNERGY® Power Entry Cable Assembly, 8-wire/4-circuit (4-2-2), shared neutral, 3 feet

- Used to interface between manufactured wiring and other wiring systems, such as building wiring, fixture wiring, or access floor module wiring
- Mates to line connector cable assemblies, power junction boxes, power distribution modules (PDMs), zone distribution modules (ZDBs) and power transition units (PTUs)

Product Classification

| | |
|------------------------------|----------------------------|
| Brand | AMPINNERGY® |
| Product Series | AMPINNERGY |
| Product Type | Power entry cable assembly |
| Regional Availability | North America |

Dimensions

| | |
|---------------------------------|------------------|
| Cord Length | 0.91 m 3.00 ft |
| Exposed Conductor Length | 12.00 in |

Electrical Specifications

| | |
|--------------------------------|-------------------------|
| Current Rating, maximum | 20.00 A |
| Voltage Rating, maximum | 125.00 Vac 250.00 Vac |

Environmental Specifications

| | |
|----------------------------|--|
| Environmental Space | Indoor |
| Safety Standard | CEC 2015 CSA 22.2 NEC 2013 UL 1286 UL 183 UL 498 |


General Specifications

| | |
|---------------------------------------|-----------------------|
| Application | Line entry connection |
| Construction Type | Corrugated hose |
| Interface, connector A | Power male plug |
| Interface, connector B | Unterminated |
| Neutral Conductor Gauge, solid | 10-12 AWG |
| Neutral Type | Shared |
| Package Quantity | 1 |
| Packaging Type | Bag |

Mechanical Specifications

| | |
|---------------|--------------------------|
| Wiring | 8-Wire/4 Circuit (4-2-2) |
|---------------|--------------------------|

Outline Drawing

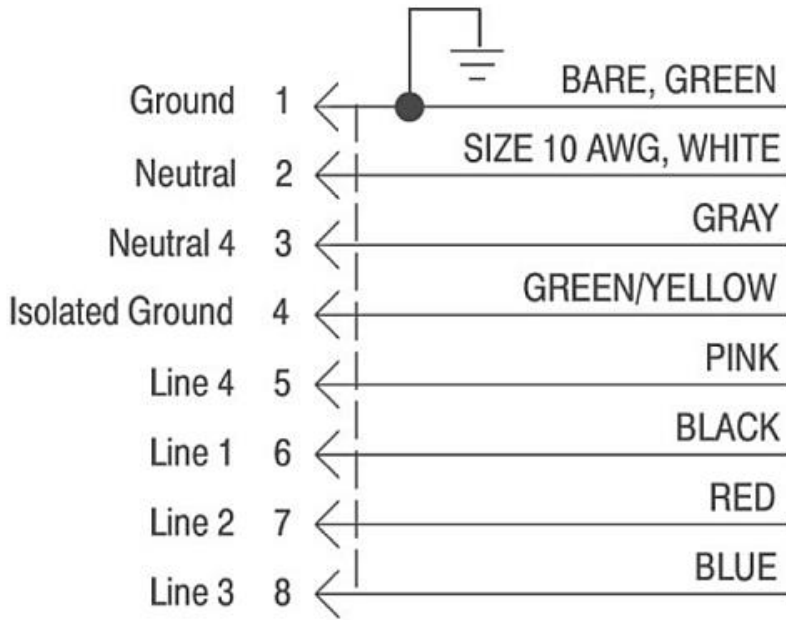

Outline Drawing

Used as an image placeholder

Regulatory Compliance/Certifications

Agency

RoHS 2011/65/EU

Classification

Compliant

