

F1-HMHF-1M-CHT



FSJ1-50A SureFlex® Jumper with interface types 4.3-10 Male and 4.3-10 Female, 1M

- **WARNING: DO NOT MATE WITH 4.1-9.5 DIN**

Product Classification

Product Series FSJ1-50A
Product Type Wireless transmission cable assembly

General Specifications

Body Style, Connector A Straight
Body Style, Connector B Straight
Interface, Connector A 4.3-10 Male
Interface, Connector B 4.3-10 Female
Length 1.000 m | 3.281 ft
Nominal Size 1/4 in
Specification Sheet Revision Level A


Electrical Specifications

3rd Order IMD Static -155.00 dBc | -112.00 dBm
3rd Order IMD Static Test Method Two +43 dBm carriers

Environmental Specifications

Immersion Test Method Meets IEC 60529:2001, IP68 in mated condition

Jumper Assembly Sample Label

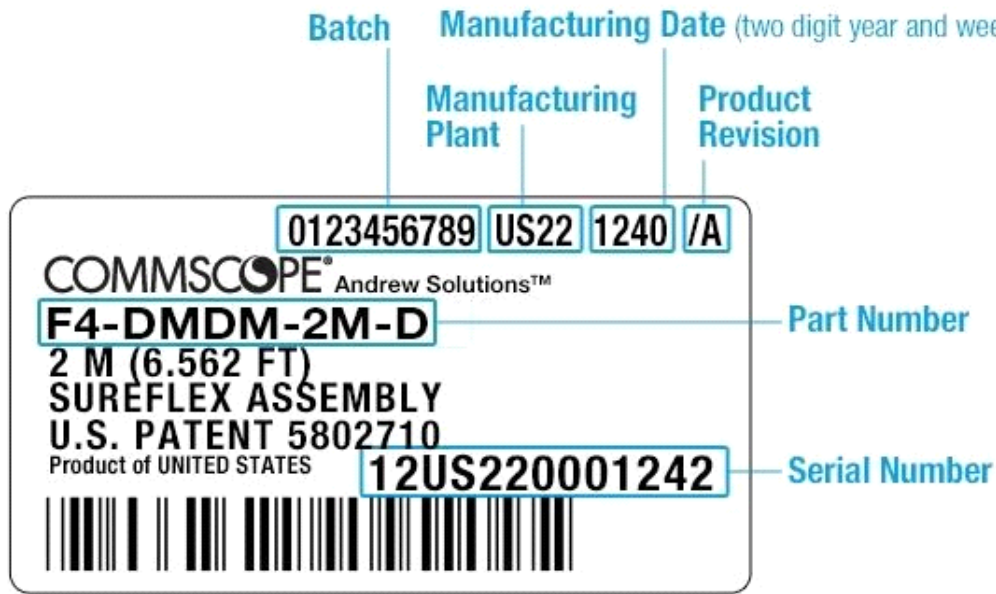

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
806–960 MHz	1.15	23.00
1710–2200 MHz	1.15	23.00
2495–2690 MHz	1.15	23.00

Regulatory Compliance/Certifications

Agency

RoHS 2011/65/EU
China RoHS SJ/T 11364-2014

Classification

Compliant by Exemption
Above Maximum Concentration Value (MCV)

