

F1A-DRDR-3-P



FSJ1-50A SureFlex® Jumper with interface types 7-16 DIN Male Right Angle and 7-16 DIN Male Right Angle, 3 ft

Product Classification

Product Series FSJ1-50A
Product Type Wireless transmission cable assembly

General Specifications

Body Style, Connector A Right angle
Body Style, Connector B Right angle
Interface, Connector A 7-16 DIN Male
Interface, Connector B 7-16 DIN Male
Length 0.914 m | 3.000 ft
Nominal Size 1/4 in
Specification Sheet Revision Level A


Electrical Specifications

3rd Order IMD Static -150.00 dBc | -107.00 dBm
3rd Order IMD Static Test Method Two +43 dBm carriers

Environmental Specifications

Immersion Test Method Meets IEC 60529:2001, IP68 in mated condition

Jumper Assembly Sample Label

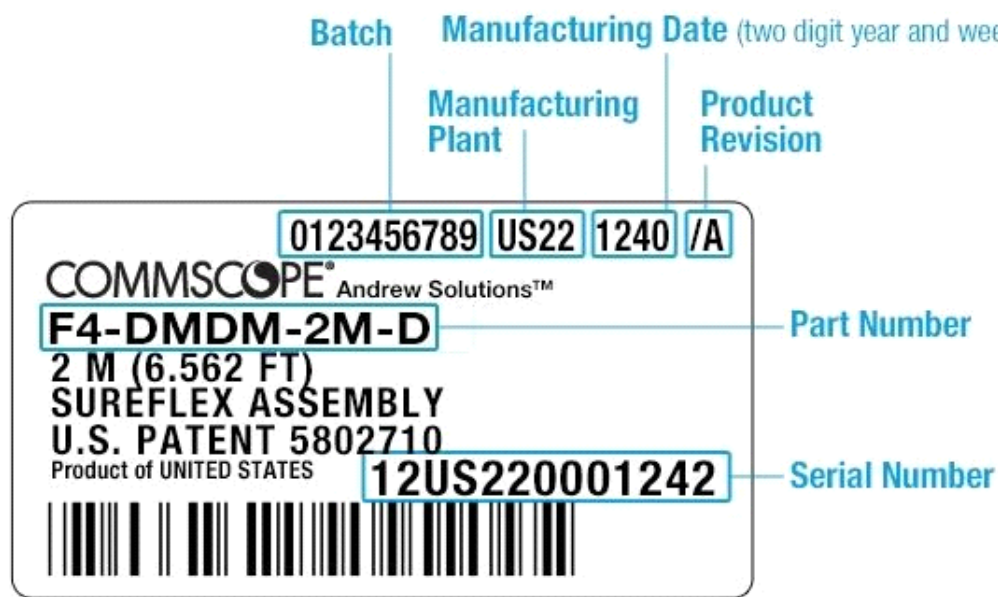

Return Loss/VSWR

Frequency Band	VSWR	Return Loss (dB)
698–960 MHz	1.15	23.00
1700–2200 MHz	1.15	23.00
2200–2700 MHz	1.15	23.00

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2011/65/EU	Compliant by Exemption
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
China RoHS SJ/T 11364-2014	Above Maximum Concentration Value (MCV)

