


SRS-STHT-SLNU-OR-D

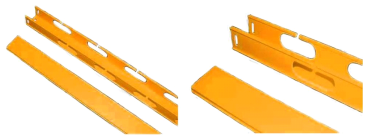

SpeedPRO™ Straight Slotted Channel with hinged cover, 30 mm x 30 mm (1.25 in x 1.25 in), 2 m (6 ft 6 in) length, orange

Product Classification

Portfolio	CommScope®
Brand	SpeedPRO™
Product Type	Fiber raceway channel, with hinged cover
Regional Availability	Asia Australia/New Zealand EMEA Latin America North America

Dimensions

System Dimensions	1.25 in x 1.25 in 30 mm x 30 mm
Length	2000.0 mm 78.7 in
Weight	0.47 kg 1.03 lb

Environmental Specifications

Flammability Rating	UL 94 V-0
Halogen Characteristics	LSZH
Safety Standard	UL

General Specifications

Color	Orange
Minimum Order Quantity	250
Package Quantity	1
Section Type	Straight section
Warranty	20 years

Mechanical Specifications

Material Type	PPO/PS
----------------------	--------