


LSA-PLUS® Copper Cable, 1 pair, 120 Ohm F/FTP, PVC, 250 m, white



Product Classification

Portfolio	CommScope®
Brand	LSA-PLUS®
Product Series	LSA-PLUS
Product Type	Twisted pair cable
Regional Availability	Australia/New Zealand EMEA

Cross Section Drawing

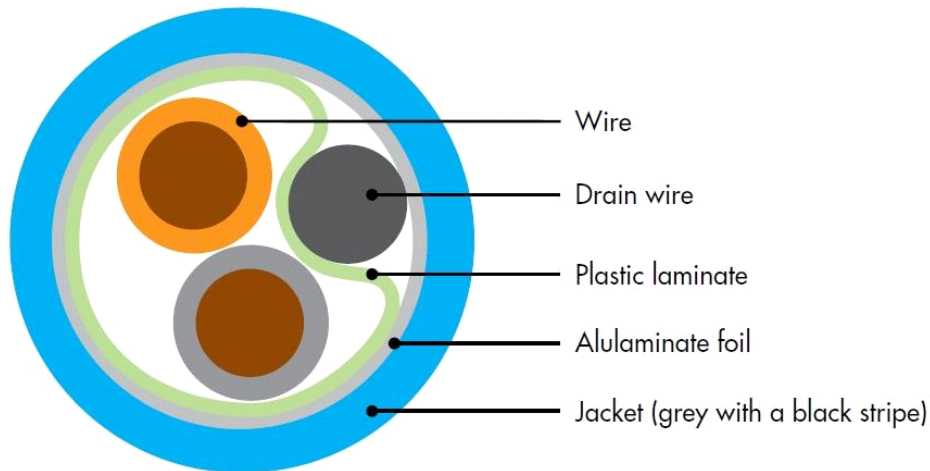

Construction Materials

Jacket Material	PVC
Conductor Material	Bare copper
Insulation Material	Foamed polyethylene (FPE)
Shield (Tape) Material	Aluminum/Poly

Dimensions

Cable Length 250 m | 820 ft
Cable Weight 8.00 kg/km
Diameter Over Jacket, nominal 2.800 mm | 0.110 in

Electrical Specifications

ANSI/TIA Category 3
Operating Voltage, maximum 250 V
Transmission Standards ANSI/TIA-568-C.2 | CENELEC EN 50288-6-1 | ISO/IEC 11801 Class E

Environmental Specifications

Operating Temperature -5 °C to +70 °C (+23 °F to +167 °F)

General Specifications

Cable Type F/FTP (shielded)
Packaging Type Reel
Pairs, quantity 1
Cable Component Type Horizontal
Jacket Color White
Conductor Type, singles Solid

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

