




640 Series Copper Cable, category 6A, 4 pair, F/UTP, LSZH, 23 AWG, 305 m reel, violet

Product Classification

Portfolio	NETCONNECT®
Product Series	640 Series
Product Type	Twisted pair cable
Regional Availability	Asia Australia/New Zealand Latin America

Cross Section Drawing

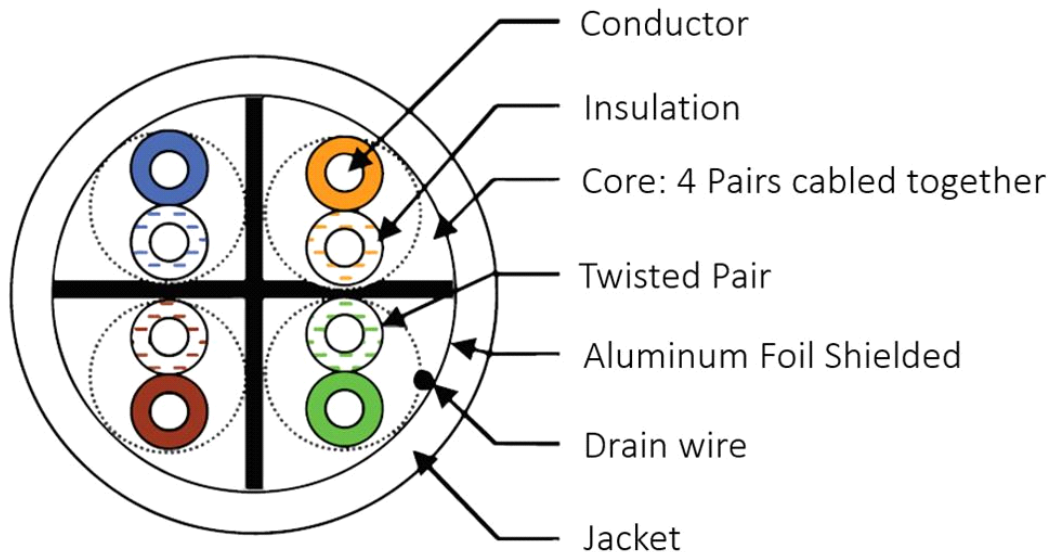

Construction Materials

Jacket Material	Low Smoke Zero Halogen (LSZH)
Conductor Material	Bare copper

Dimensions

Cable Length	305 m 1000 ft
Cable Weight	60.10 kg/km

Electrical Specifications

ANSI/TIA Category	6A
--------------------------	----

Characteristic Impedance	100 ohm
Characteristic Impedance Tolerance	±15 ohm
dc Resistance, maximum	66.58 ohms/km
Delay Skew, maximum	45 ns
Mutual Capacitance	5.6 nF/100 m @ 500 MHz
Nominal Velocity of Propagation (NVP)	64 %
Operating Voltage, maximum	80 V
Transmission Standards	ANSI/TIA-568-C.2 CENELEC EN 50288-6-1 ISO/IEC 11801 Class EA

Environmental Specifications

Smoke Test Method	IEC 61034-2
Acid Gas Test Method	IEC 60754-2
Flame Test Method	IEC 60332-1

General Specifications

Cable Type	F/UTP (shielded)
Packaging Type	Reel
Pairs, quantity	4
Cable Component Type	Horizontal
Jacket Color	Violet
Conductor Type, singles	Solid

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

