

Pressure Window for WR229, 3.3–4.9 GHz, mates to PDR40

Product Classification

Product Type Rectangular waveguide, pressure window

Electrical Specifications

Operating Frequency Band 3.3 – 4.9 GHz


VSWR 1.04

General Specifications

Component Pressure Window
Waveguide Size WR229 | WG11 | R40
Interface UDR40
Mates to Interface PDR40

Interface

Mates to Interface

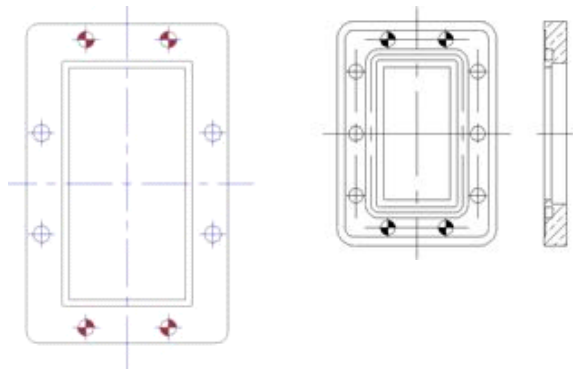

Regulatory Compliance/Certifications

Agency ISO 9001:2015 **Classification** Designed, manufactured and/or distributed under this quality management system

