


D090CCSG

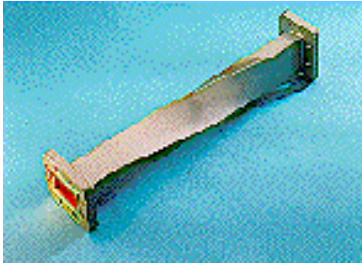

90° Rigid Twist for WR90, 8.2–12.4 GHz, with interface types CPR90G and CPR90G, 8 in, gray

Product Classification

Product Type Rectangular waveguide, rigid twist

Electrical Specifications


Operating Frequency Band 8.2 – 12.4 GHz

VSWR 1.06


General Specifications

Component 90° Rigid Twist
Waveguide Size WR90 | WG16 | R100
Finish Gray
Interface CPR90G
Interface 2 CPR90G
Length 203 mm | 8 in


Component

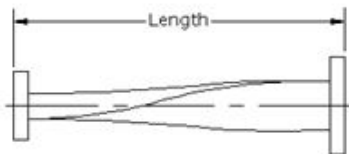

Interface

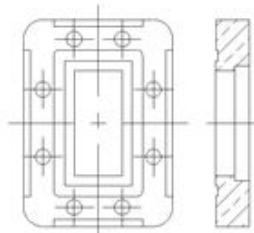

Interface 2

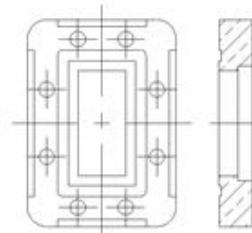

Regulatory Compliance/Certifications

Agency ISO 9001:2015
Classification Designed, manufactured and/or distributed under this quality management system

