


D137CCSG

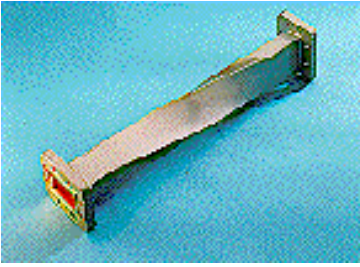

90° Rigid Twist for WR137, 5.85–8.2 GHz, with interface types CPR137G and CPR137G, 12 in, gray

Product Classification

Product Type Rectangular waveguide, rigid twist

Electrical Specifications


Operating Frequency Band 5.85 – 8.2 GHz

VSWR 1.06


General Specifications

Component 90° Rigid Twist
Waveguide Size WR137 | WG14 | R70
Finish Gray
Interface CPR137G
Interface 2 CPR137G
Length 305 mm | 12 in


Component

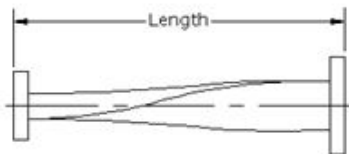

Interface

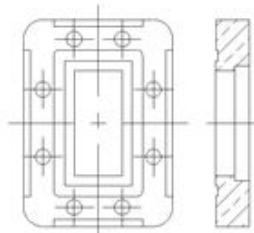

Interface 2

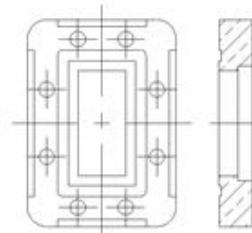

Regulatory Compliance/Certifications

Agency ISO 9001:2015
Classification Designed, manufactured and/or distributed under this quality management system

