


3-1859676-4

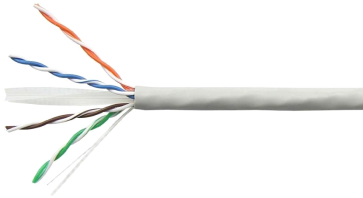


Copper Cable, category 6A, 4 pair, U/UTP, CM, 23 AWG, 1000 ft, gray

Product Classification

Portfolio	NETCONNECT®
Product Type	Twisted pair cable
Regional Availability	Asia

Cross Section Drawing

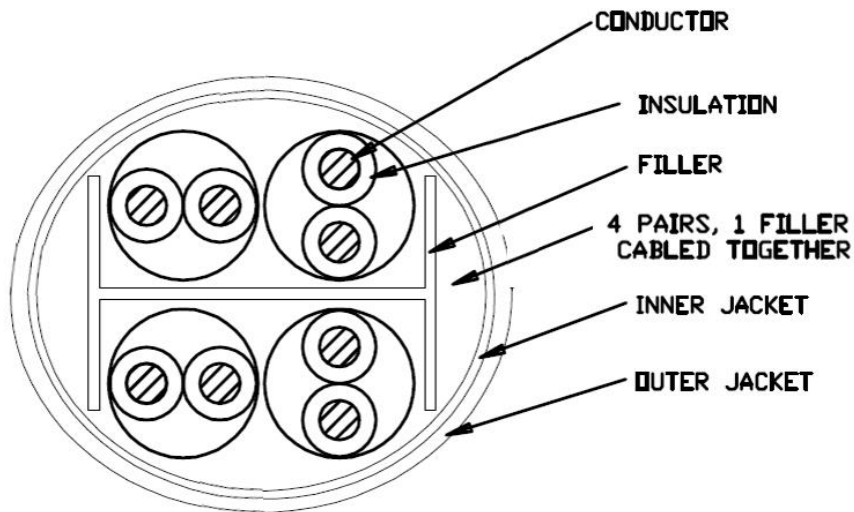

Construction Materials

Jacket Material	PVC
Conductor Material	Bare copper

Dimensions

Cable Length	305 m 1000 ft
Diameter Over Jacket, nominal	8.100 mm 0.319 in

Electrical Specifications

ANSI/TIA Category	6A
--------------------------	----

Operating Voltage, maximum 80 V
Transmission Standards ANSI/TIA-568-C.2 | CENELEC EN 50288-6-1 | ISO/IEC 11801 Class E

Environmental Specifications

Flame Test Method NEC Article 800 | UL 444

General Specifications

Cable Type U/UTP (unshielded)
Packaging Type Reel
Pairs, quantity 4
Cable Component Type Horizontal
Jacket Color Gray
Conductor Gauge, singles 23 AWG
Conductor Type, singles Solid

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

