


1427227-3

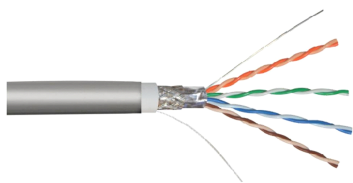


Copper Cable, category 5e, 4 pair, SF/UTP, CM, 24 AWG solid, 1000 ft, gray

Product Classification

Portfolio	NETCONNECT®
Product Type	Twisted pair cable
Regional Availability	Asia EMEA

Cross Section Drawing

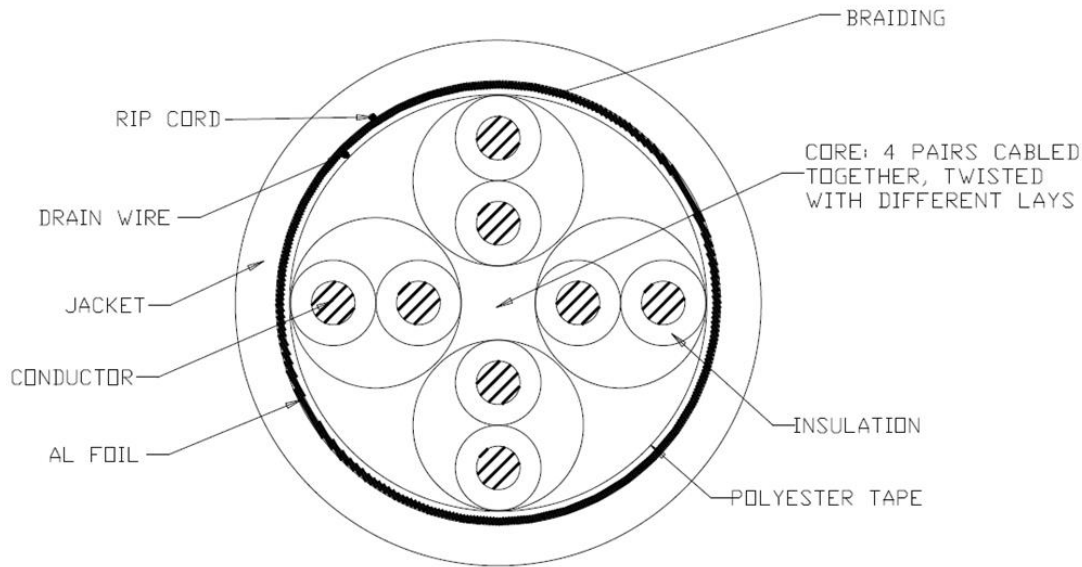

Construction Materials

Jacket Material	PVC
Conductor Material	Bare copper
Drain Wire Material	Tinned copper
Insulation Material	Polyolefin
Ripcord Material	Polyester
Shield (Braid) Material	Tinned copper
Shield (Tape) Material	Aluminum/Polyester

Dimensions

Cable Length	305 m 1000 ft
Diameter Over Jacket, nominal	6.500 mm 0.256 in
Jacket Thickness	0.570 mm 0.022 in

Electrical Specifications

ANSI/TIA Category	5e
Operating Voltage, maximum	80 V
Transmission Standards	ANSI/TIA-568-C.2

Environmental Specifications

Environmental Space	Non-plenum
----------------------------	------------

Fire Safety Listing	CM
Flame Test Method	NEC Article 800 UL 444
Safety Standard	UL

General Specifications

Cable Type	SF/UTP (shielded)
Packaging Type	Reel
Pairs, quantity	4
Cable Component Type	Horizontal
Jacket Color	Gray
Conductor Gauge, singles	24 AWG
Conductor Type, singles	Solid
Conductors, quantity	8

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU
CENELEC

Classification
Compliant

