


HomeConnect® F Type Port Non-locking Terminator, brass

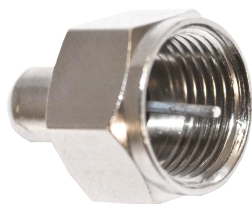

Product Classification

Brand	HomeConnect®
Product Type	Terminator

Environmental Specifications

Operating Temperature	-40 °C to +60 °C (-40 °F to +140 °F)
Safety Standard	CE EN 60728-4 SCTE

Electrical Specifications

Impedance	75 ohm
Operating Frequency Band	5 – 1002 MHz
Return Loss, minimum	30 dB
Shielding Effectiveness, minimum	100 dB

General Specifications

Device Type	Non-locking terminator
Parking Port	Not included

Dimensions

Contact Pin Diameter	0.762 mm 0.030 in
-----------------------------	---------------------

Mechanical Specifications

Material Type	Brass
Plating	Nickel

Packed Dimensions

Carton Quantity	5000
Height	190.50 mm 7.50 in
Length	330.20 mm 13.00 in

SVF59TG

Width 241.30 mm | 9.50 in
Shipping Weight 19.05 kg | 42.00 lb

Regulatory Compliance/Certifications

Agency	Classification
RoHS 2011/65/EU	Compliant
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

