


RJ45 Coupler Assembly, category 3, 8-position, in-line, keyed, black

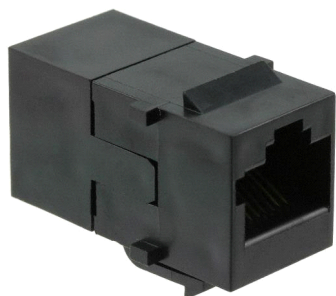

Product Classification

Portfolio	NETCONNECT®
Product Type	Modular jack coupler
Regional Availability	Asia Latin America North America

Dimensions

Depth	30.73 mm 1.21 in
Height	19.05 mm 0.75 in
Width	14.48 mm 0.57 in

Electrical Specifications

ANSI/TIA Category	3
Transmission Standard	ANSI/TIA-568-C.2 ISO/IEC 11801 Class C

Environmental Specifications

Flammability Rating	UL 94 V-0
----------------------------	-----------

General Specifications

Cable Type	Unshielded
Color	Black
Package Quantity	1
Panel Cutout, recommended	14.86 x 19.30 mm (0.59 x 0.76 in)
Panel Thickness, recommended	1.60 mm

Mechanical Specifications

Conductor Type	Solid Stranded
Contact Base Material	Phosphor bronze
Contact Plating Material	Gold
Contact Plating Thickness	1.27 µm

555376-1

Material Type	Polycarbonate
Outlet Feature	Keyed
Outlet Type	Inline
Termination Type	IDC
Wiring	T568A T568B

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

