

7-16 DIN Female High Power Termination Load, 70–2700 MHz

Product Classification

Product Type Termination load


General Specifications

Device Type Termination Load
Interface 7-16 DIN Female
Color Silver

Electrical Specifications

Operating Frequency Band 70 – 2700 MHz
Average Power, maximum 175 W
Impedance 50 ohm
Peak Power, maximum 2 kW
Return Loss, minimum 20.0 dB
VSWR 1.22:1

Derating Curve

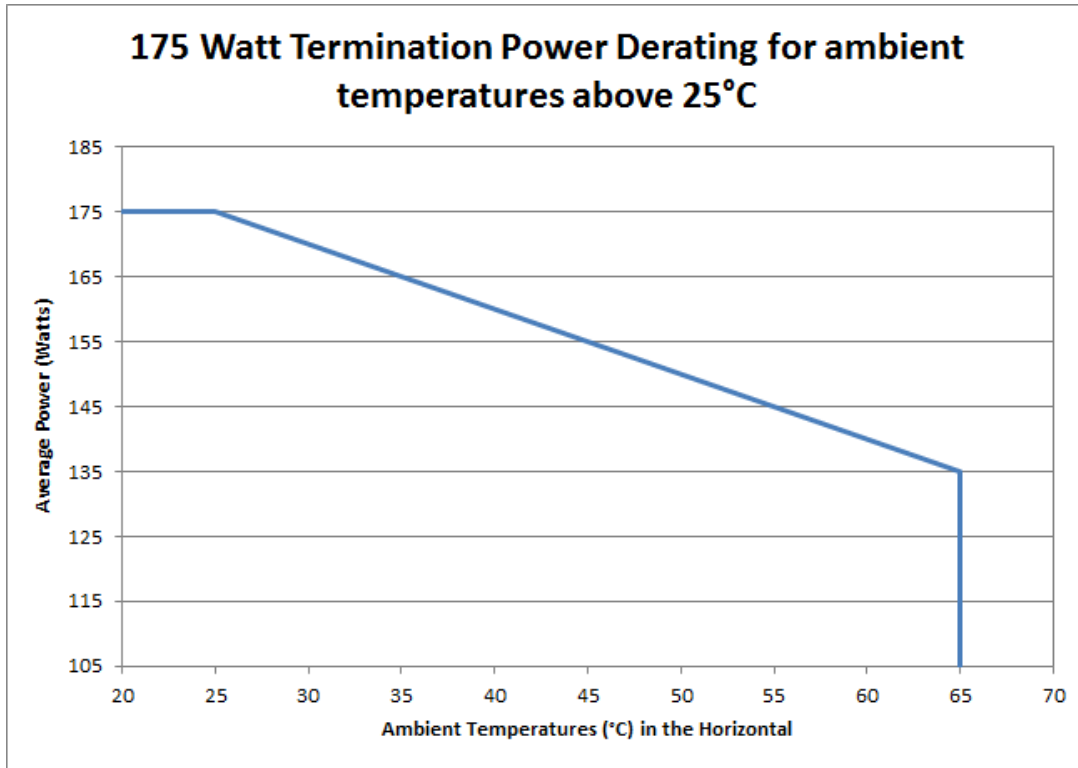

Environmental Specifications

Ingress Protection Test Method IEC 60529:2001, IP30

Operating Temperature -33 °C to +65 °C (-27.4 °F to +149 °F)

Packed Dimensions

Height 242.0 mm | 9.5 in

Length 130.0 mm | 5.1 in

Width 165.0 mm | 6.5 in

Shipping Weight 3.70 kg | 8.16 lb

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

