

# T-2-UW-43-F

Termination Load, 0–6000 MHz



## Product Classification

**Product Type** Termination load


## General Specifications

**Device Type** Termination Load  
**Interface** 4.3-10 Female  
**Color** Black

## Electrical Specifications

**Operating Frequency Band** 0 – 6000 MHz  
**Average Power at Temperature** 1.7 W @ 60 °C  
**Average Power, maximum** 2 W  
**Impedance** 50 ohm  
**VSWR** 1.15

## Derating Curve

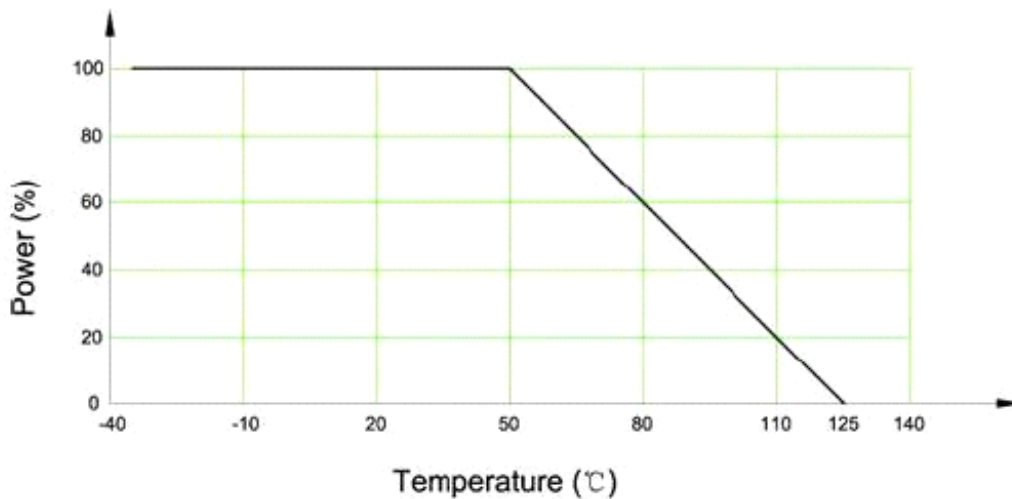

# T-2-UW-43-F

---

## Mechanical Specifications

<b>Inner Contact Plating</b>	Silver
<b>Outer Contact Plating</b>	Trimetal

## Environmental Specifications

<b>Application</b>	Indoor/Outdoor
<b>Ingress Protection Test Method</b>	IEC 60529:2001, IP65
<b>Operating Temperature</b>	-35 °C to +50 °C (-31 °F to +122 °F)
<b>Relative Humidity</b>	Up to 100%

## Dimensions

<b>Diameter, maximum</b>	20.00 mm   0.79 in
<b>Length</b>	42.00 mm   1.65 in
<b>Net Weight</b>	50.00 g   0.11 lb

## Packed Dimensions

<b>Height</b>	68.0 mm   2.7 in
<b>Length</b>	58.0 cm   22.8 in
<b>Width</b>	53.0 mm   2.1 in
<b>Shipping Weight</b>	70.00 g   0.15 lb

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
RoHS 2011/65/EU	
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

