


ARA-22

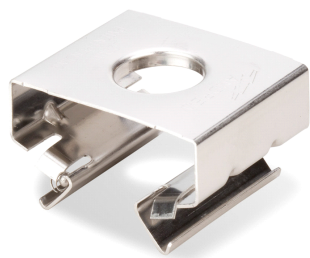

Anchor Rail Adapter, 22 mm

Product Classification

Product Type Adapter

Dimensions

Outside Length 1178.56 mm | 46.40 in

Outside Width 1285.24 mm | 50.60 in

General Specifications

Adapter Type Adapter

Material Type Stainless steel

Ordering Note CommScope® non-standard product

Package Quantity 10

Mechanical Specifications

Material Thickness 2.591 mm | 0.102 in

Maximum Loading Double stack, 1-5/8 in cable

Mounting 3/4 in through hole

Packed Dimensions

Height 14.0 cm | 5.5 in

Length 8.0 cm | 3.1 in

Shipping Weight 0.97 kg | 2.14 lb

Width 14.0 cm | 5.5 in

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system

