


Butterfly Hanger for 1-1/4 in coaxial cable and elliptical waveguide 64

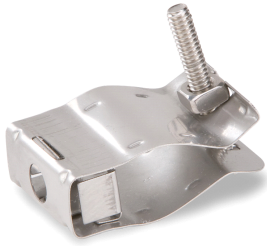

Product Classification

Product Type Hanger kit

Dimensions

Nominal Size 1-1/4 in
Compatible Diameter, maximum 43.180 mm | 1.700 in
Compatible Diameter, minimum 37.592 mm | 1.480 in
Height 59.00 mm | 2.32 in
Length 76.20 mm | 3.00 in
Width 38.10 mm | 1.50 in

Electrical Specifications

DTF Effect 0.1 dB
Return Loss Effect 0.1 dB

Environmental Specifications

Operating Temperature -40 °C to +85 °C (-40 °F to +185 °F)

General Specifications

Hanger Type Standard butterfly hanger
Cables per Hanger 1
Color Silver
Material Type Stainless steel
Ordering Note CommScope® standard product in the United States and Canada
Package Quantity 10

Mechanical Specifications

Corrosion Resistance, minimum with no degradation =500 hours in salt spray chamber
Mounting 3/8 in (M10) drilled cable ladder

42396A-1

Vibration Survival =4 hours at resonant frequency
Environmental Strength Capability Double cable weight

Packed Dimensions

Height 26.0 cm | 10.2 in
Length 9.0 cm | 3.5 in
Shipping Weight 0.53 kg | 1.16 lb
Width 9.0 cm | 3.5 in

Regulatory Compliance/Certifications

Agency

RoHS 2011/65/EU
ISO 9001:2015
China RoHS SJ/T 11364-2014

Classification

Compliant
Designed, manufactured and/or distributed under this quality management system
Below Maximum Concentration Value (MCV)

