


Three-way Snap-in Stand-off Adapter for 1–2 in round members

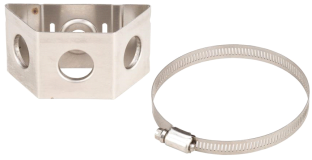

Product Classification

Product Type Adapter

Dimensions

Compatible Diameter, maximum 50.800 mm | 2.000 in
Compatible Diameter, minimum 25.400 mm | 1.000 in
Outside Length 1975.10 mm | 77.76 in
Outside Width 1012.44 mm | 39.86 in

General Specifications

Adapter Type Adapter
Material Type Stainless steel
Ordering Note CommScope® non-standard product
Package Quantity 10

Mechanical Specifications

Material Thickness 2.591 mm | 0.102 in
Maximum Loading Double stack, 1-5/8 in cable
Mounting 3/4 in through hole

Packed Dimensions

Height 12.0 cm | 4.7 in
Length 1.0 cm | 0.4 in
Shipping Weight 0.58 kg | 1.28 lb
Width 11.0 cm | 4.3 in

Regulatory Compliance/Certifications

Agency ISO 9001:2015
Classification Designed, manufactured and/or distributed under this quality management system



Included Products

31670-1 — Round Member Adapter for 1–2 in round members

SA-38 — Universal Stand-off Adapter, 3 Hanger Points

TTS3-34 — Three-way Stand-off Adapter for 3–4 in round members

- UAAI — Universal Angle Adapter Insert
- 31670-3 — Round Member Adapter for 3–4 in round members
- SA-38 — Universal Stand-off Adapter, 3 Hanger Points

TTS3-45 — Three-way Stand-off Adapter for 4–5 in round members

- UAAI — Universal Angle Adapter Insert
- SA-38 — Universal Stand-off Adapter, 3 Hanger Points
- 31670-4 — Round Member Adapter for 4–5 in round members

TTS3-56 — Three-way Stand-off Adapter for 5–6 in round members

- UAAI — Universal Angle Adapter Insert
- SA-38 — Universal Stand-off Adapter, 3 Hanger Points
- 31670-5 — Round Member Adapter for 5–6 in round members

TTS3-153 — Three-way Stand-off Adapter for 1.5–3 in round members

- UAAI — Universal Angle Adapter Insert
- SA-38 — Universal Stand-off Adapter, 3 Hanger Points

TTS3-7515 — Three-way Stand-off Adapter for 0.75–1.5 in round members

- UAAI — Universal Angle Adapter Insert
- SA-38 — Universal Stand-off Adapter, 3 Hanger Points
- 31670-1 — Round Member Adapter for 1–2 in round members