


UGBA-36

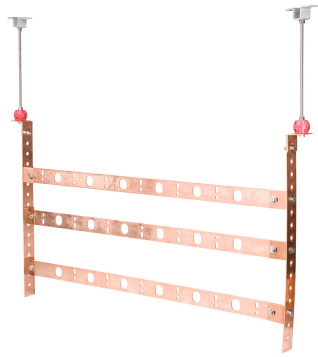

Universal Ground Bar Assembly, three six-position ground bars, for 7-16 DIN, type N, or bolt-grounded surge arrestors

Product Classification

Product Type Grounding bar

Dimensions

Height 50.80 mm | 2.00 in
Length 457.20 mm | 18.00 in
Hole Size 1.3 in

General Specifications

Material Type Copper
Hole Distance, center to center 63.50 mm | 2 1/2 in
Includes Bulkhead mounting bar | Grounding bar | Insulators | Mounting brackets | Threaded rod | Universal hardware
Ordering Note CommScope® non-standard product
Package Quantity 1

Mechanical Specifications

Material Thickness 6.350 mm | 1/4 in

Packed Dimensions

Height 654.1 mm | 25.8 in
Length 57.2 mm | 2.3 in
Shipping Weight 7.70 kg | 16.98 lb
Width 247.7 mm | 9.8 in

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

