


UGBA-DIN-36

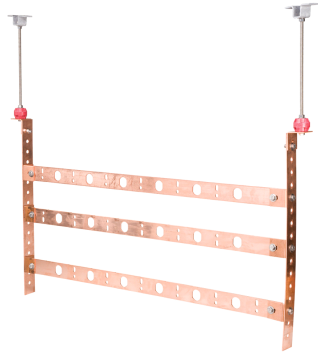

Universal Ground Bar Assembly, three six-position ground bars, for 7-16 DIN or bolt-grounded surge arrestors

Product Classification

Product Type Grounding bar

Dimensions

Height 50.80 mm | 2.00 in
Length 1003.30 mm | 39.50 in
Hole Size 1.3 in

General Specifications

Material Type Copper
Hole Distance, center to center 137.16 mm | 5.40 in
Includes Bulkhead mounting bar | Grounding bar | Insulators | Mounting brackets | Threaded rod | Universal hardware
Ordering Note CommScope® non-standard product
Package Quantity 1

Mechanical Specifications

Material Thickness 3.175 mm | 1/8 in

Packed Dimensions

Height 1282.7 mm | 50.5 in
Length 68.6 mm | 2.7 in
Shipping Weight 8.60 kg | 18.96 lb
Width 68.6 mm | 2.7 in

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

