


# FST-D-FT

---

Fiber Optic Splice Tray, 12 splice capacity

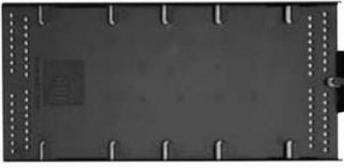

## Product Classification

**Product Type** Fiber splice tray  
**Regional Availability** Latin America | North America

## Environmental Specifications

**Storage Temperature** -40 °C to +85 °C (-40 °F to +185 °F)

## General Specifications

**Application** For use with FDF splice panels  
**Color** Black  
**Splicing Capacity, maximum** 12

## Regulatory Compliance/Certifications

**Agency**  
RoHS 2011/65/EU

**Classification**  
Compliant

