



Pulling Eye for Flexible Conduit and HDPE Duct, size 0.75, Duct range 17 to 24 mm

- Designed for the wide variety of flex-, sub- and inner-ducts used in telecom and utility construction
- More linear threads per inch for better grip on duct
- Wider application range per size for fewer sizes to handle
- Buttressed threads hold duct more securely
- For smooth-wall, ribbed and corrugated ducts


Product Classification

Brand	Jackmoon®
Product Type	Pulling eye
Regional Availability	Asia Australia/New Zealand EMEA Latin America North America

General Specifications

Package, quantity	1
Packaging Type	Bag Carton

Dimension Drawing

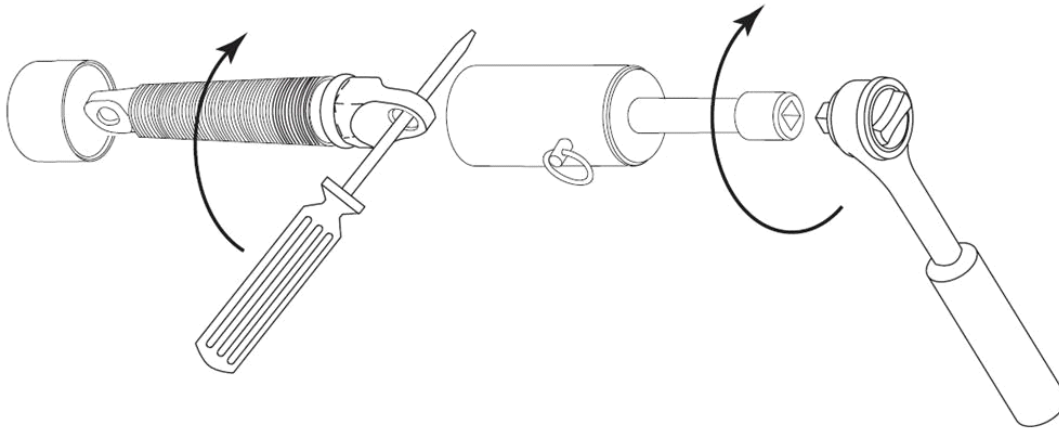

Dimension Drawing Used as an image placeholder

Mechanical Specifications

Material Type	Stainless steel
----------------------	-----------------

Dimensions

Conduit Inner Diameter, maximum 24.00 mm

Conduit Inner Diameter, minimum 17.00 mm

Regulatory Compliance/Certifications

Agency

RoHS 2011/65/EU

Classification

Compliant

