



Pulling Eye for Flexible Conduit and HDPE Duct, size 1.50, Duct range 35 to 44 mm

- Designed for the wide variety of flex-, sub- and inner-ducts used in telecom and utility construction
- More linear threads per inch for better grip on duct
- Wider application range per size for fewer sizes to handle
- Buttressed threads hold duct more securely
- For smooth-wall, ribbed and corrugated ducts


## Product Classification

<b>Brand</b>	Jackmoon®
<b>Product Type</b>	Pulling eye
<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America

## General Specifications

<b>Package, quantity</b>	1
<b>Packaging Type</b>	Bag   Carton

## Dimension Drawing

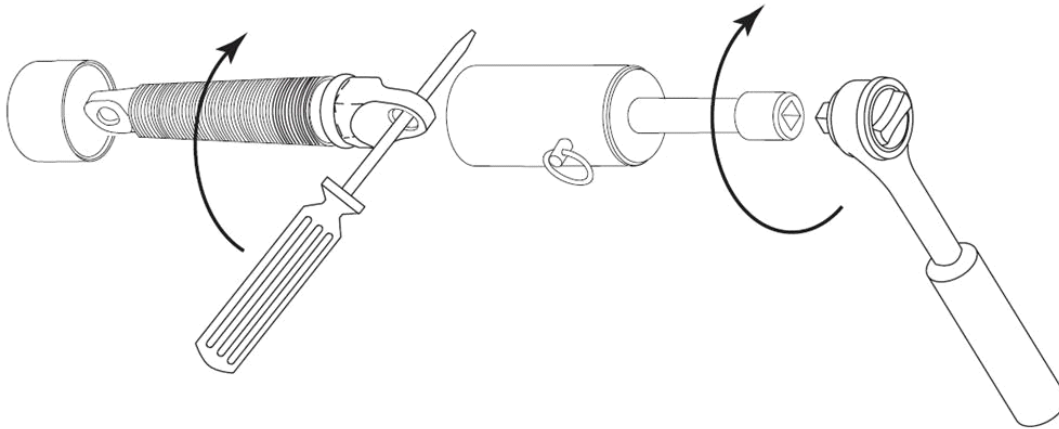

**Dimension Drawing** Used as an image placeholder

## Mechanical Specifications

<b>Material Type</b>	Stainless steel
----------------------	-----------------

## Dimensions

**Conduit Inner Diameter, maximum** 44.00 mm

**Conduit Inner Diameter, minimum** 35.00 mm

## Regulatory Compliance/Certifications

**Agency**

RoHS 2011/65/EU

**Classification**

Compliant

