



MPO Trunk Cable, 192 fiber, 12f MPO (no-pins), SM, Riser, 10 m

- Each assembly is pre-tested in the factory, and test performance data is traceable via a bar code to a test data base
- Improved flexibility using flexible breakout tube and improved breakout construction optimized for use with Q3000/EHD chassis and NGF frames
- Optimized for efficient deployment of high speed backbone links in advanced data centers, simplifying day-2 activities

Product Classification

Portfolio	NETCONNECT®
Product Series	HFT
Product Type	Fiber trunk cable assembly
Regional Availability	Latin America North America

Construction Materials

Fiber Type	G.657.A1
Total Fibers, quantity	192
Jacket Color	Yellow
Fiber Mode	Singlemode

Dimensions

Breakout Length Note	Optimized for Q3000 Fiber Chassis
Breakout Length Tolerance, connector A	±1.00 in
Breakout Length Tolerance, connector B	±1.00 in
Breakout Length, connector A	787.40 mm 31.00 in
Breakout Length, connector B	863.60 mm 34.00 in
Cord Length	10.00 m 32.81 ft
Diameter Over Jacket	17.27 mm 0.68 in

Environmental Specifications

Environmental Space	Riser
----------------------------	-------

General Specifications

Interface, connector A	MPO-12/APC Female
Interface, connector B	MPO-12/APC Female
Color, connector A	Green
Color, connector B	Green
Interface Feature, connector A	Unpinned


HFT-ANNBS1010.0MHH

Interface Feature, connector B	Unpinned
Color, boot A	Black
Color, boot B	Black
Connector A, quantity	16
Connector B, quantity	16
Includes	Pulling grip
Package Quantity	1
Polarity	Pairs, straight

Optical Performance

Insertion Loss, maximum, connector A	0.35 dB
Insertion Loss, maximum, connector B	0.35 dB
Return Loss, minimum, connector A	65.00 dB
Return Loss, minimum, connector B	65.00 dB

Outline Drawing

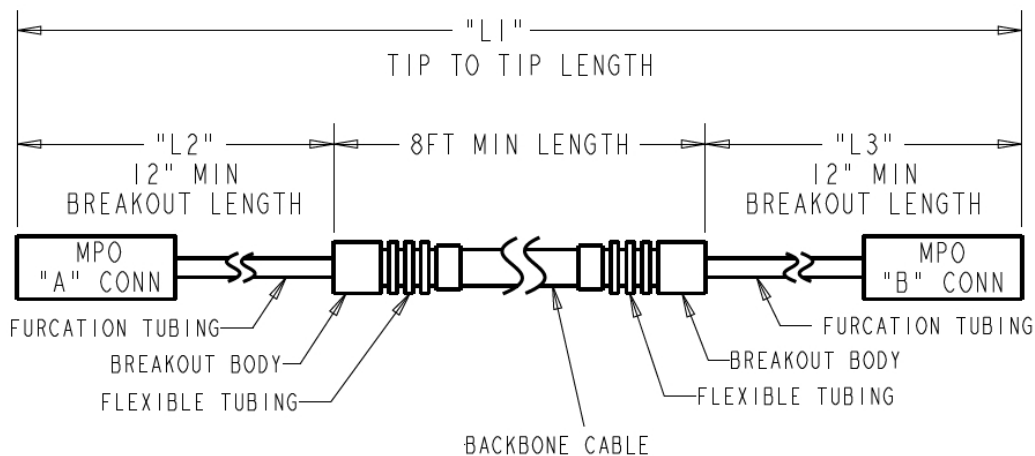

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

