


FST-D-MT-AC

Fiber Optic Splice Tray, 24 splice capacity, ribbon mass fusion

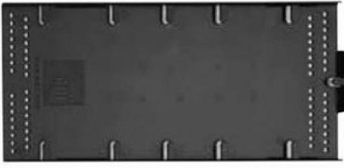

Product Classification

Product Type Fiber splice tray
Regional Availability Latin America | North America

Environmental Specifications

Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

General Specifications

Application For use with FDF splice panels
Color Black
Splicing Capacity, maximum 24
Splicing Type Mass fusion, ribbon

Regulatory Compliance/Certifications

Agency
RoHS 2011/65/EU

Classification
Compliant

