


FD3-AC144J00JBDP1BB-US

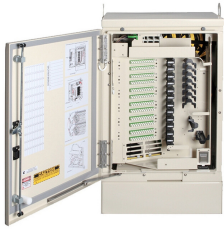

Standard FDH3000, 132F loaded bottom pole mounted cabinet, SC/APC, PNP splitter capable, OSP Dry Dielectric Loose Tube Cable, 200ft stub, using 1x144F cable containing both 1x132 distribution and a 1x12F feeder, Build America Buy America (BABA) Compliant

- *CommScope intends to release this product at a future date. At such time, this product will comply with the requirements of the Build America, Buy America Act and/or applicable waivers. Compliance requirements and waiver applicability vary based on government funding program. Check the laws and regulations for your specific program.

Product Classification

Regional Availability	North America
Product Type	Fiber distribution hub
Product Series	FDH 3000
Government Requirements	Build America Buy America (BABA) coming soon*

General Specifications

Access	Front
Cable Type	Dry Dielectric - Loose Tube
Color	Putty white
Distribution Cables, quantity	1
Distribution Ports, quantity	144
Fibers per Distribution Cable, quantity	132
Fibers per Feeder Cable, quantity	12
Interface, Input	SC
Interface Feature, Input	APC
Location of Manufacturing	Coming soon
Mounting	Pole
Splitter Slots, quantity	18

Dimensions

Height	914.4 mm 36 in
Width	533.4 mm 21 in

FD3-AC144J00JBDDP1BB-US

Depth	355.6 mm 14 in
Cable Length	60.96 m 200 ft
Enclosure Size	Extra small

Material Specifications

Finish	Powder coated
Material Type	Aluminum

Environmental Specifications

Environmental Space	Above ground Aerial
----------------------------	-----------------------

Packaging and Weights

Packaging quantity	1
Packaging Type	Pallet