


FFWLASC42

Base Product

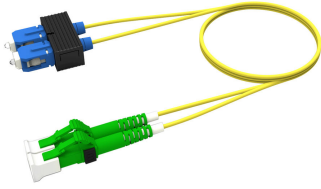

Singlemode LC/APC to SC/UPC, Fiber Patch Cord, 1.6 mm Duplex, Dual Rated Low Smoke Zero Halogen (LSZH)/Riser

Product Classification

| | |
|------------------------------|--|
| Regional Availability | Asia Australia/New Zealand Europe Latin America Middle East /Africa North America |
| Portfolio | CommScope® |
| Product Type | Fiber patch cord, duplex |
| Product Brand | SYSTIMAX InstaPATCH® 360 |
| Product Series | FFW |
| Ordering Note | For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration |

General Specifications

| | |
|-------------------------------|----------|
| Connector A, quantity | 2 |
| Color, boot A | Green |
| Color, connector A | Green |
| Connector B, quantity | 2 |
| Color, boot B | Blue |
| Color, connector B | Blue |
| Interface, Connector A | LC/APC |
| Interface, Connector B | SC/UPC |
| Jacket Color | Yellow |
| Polarity | Method B |
| Total Fibers, quantity | 2 |

Dimensions

| | |
|--|---------|
| Cable Assembly Length Range (m) | 1 – 999 |
|--|---------|

FFWLASC42

Included Products

- 760021675
N-002-ZC-8W-F16YL/E - Fiber Indoor Cable, TeraSPEED® 1.6mm Low Smoke Zero Halogen Riser, 2-fiber Zipcord, Singlemode G.652.D and G.657.A1, Feet jacket marking, Yellow jacket color, Eca Flame Rating
- 860637445 - LC/APC Connector, Singlemode, Green
- 860648965 - SC/UPC Connector, Singlemode, Blue