

UPGLCLCCL

Base Product

Ultra Low Loss (ULL) Singlemode LC/UPC to LC/UPC Armored Pre-terminated Trunk Cable, 96-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand China Europe India Latin America Middle East/Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Connector A, quantity	96
Color, boot A	Blue
Color, connector A	Blue
Connector B, quantity	96
Construction Type	Ultra Low Loss (ULL) armored trunk/extension/cross-connect, indoor
Furcation Color	Yellow
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Yellow
Total Fibers, quantity	96

Dimensions

Cable Assembly Length Range (m)	7 – 999
Cable Assembly Length Range (ft)	25 – 999

Ordering Tree

UPGLCLCCL

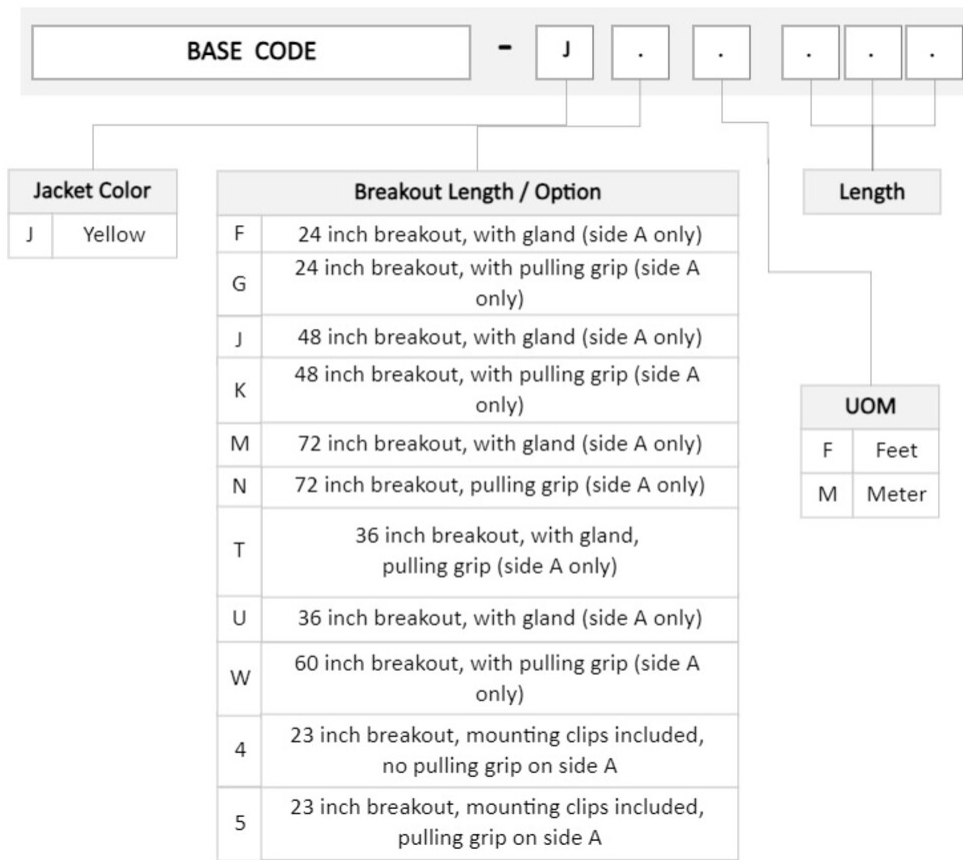

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Plenum

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

UPGLCLCCL

Included Products

- 760256105
N-096-MZ-8G1-F12YL/20T/B2 – Fiber indoor cable, Riser/LSZH rated MPO Trunk, interlocking aluminum armored, Singlemode G.657.A2/B2, 96 fiber, Feet jacket marking, Yellow jacket color, B2ca flame rating
- 860637435 – LC/UPC Connector, Singlemode, Blue, Short Boot