


# ARGRPLA7R

## Base Product

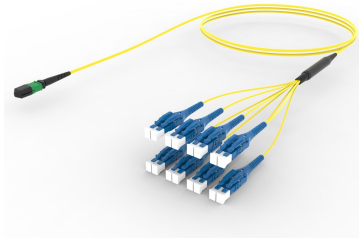

Ultra Low Loss Method A Singlemode MPO16 Non-Pinned to LC/APC, Fiber Cable Assembly, Low Smoke Zero Halogen/Riser

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | China | Europe | India | Latin America | Middle East/Africa | North America

### Portfolio

CommScope®

### Product Type

Fiber array cable assembly

### Product Brand

Propel | SYSTIMAX ULL

### Ordering Note

For additional jacket colors, please contact a CommScope Sales Representative | For lengths greater than 999 ft (304 m), orders must be in meters | Minimum length may vary based on cable configuration

## General Specifications


<b>Connector A, quantity</b>	1
<b>Color, boot A</b>	Black
<b>Color, connector A</b>	Green
<b>Connector B, quantity</b>	16
<b>Color, boot B</b>	Green
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-16/APC Female
<b>Interface Feature, connector B</b>	Uniboot
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method A
<b>Fibers per Subunit, quantity</b>	16
<b>Total Fibers, quantity</b>	16

## Dimensions

# ARGRPLA7R

<b>Breakout Length</b>	12 in   24 in   36 in   48 in   60 in   72 in
<b>Cable Assembly Length Range (m)</b>	1 – 304
<b>Cable Assembly Length Range (ft)</b>	2 – 999

## Ordering Tree

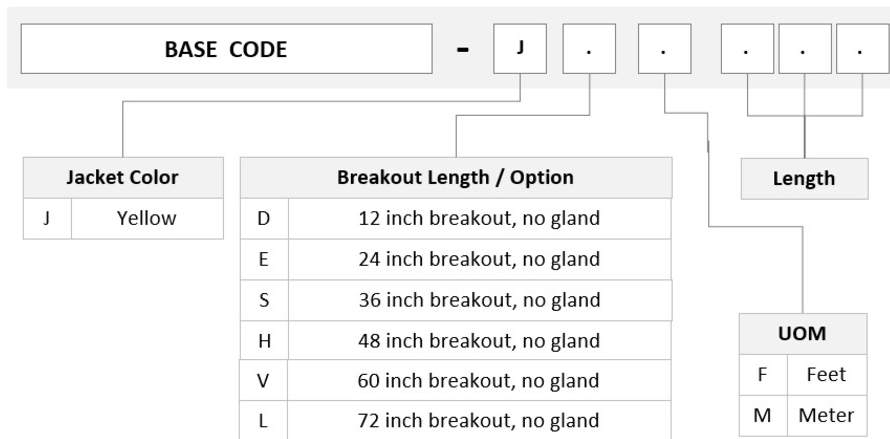

## Mechanical Specifications

<b>Cable Retention Strength, maximum</b>	11.24 lb @ 0 °   4.40 lb @ 90 °
--	---------------------------------

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	G.657.A2, TeraSPEED®

## Environmental Specifications

<b>Operating Temperature</b>	-10 °C to +60 °C (+14 °F to +140 °F)
<b>Environmental Space</b>	Dual Rated LSZH/Riser   Indoor

## Regulatory Compliance/Certifications

<b>Agency</b>	<b>Classification</b>
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

## Included Products

760251072 N-016-MP-8G1-F30YL/D	-	Fiber indoor cable, TeraSPEED® Low Smoke Zero Halogen Riser for Light Duty MPO Patchcords, 16 fiber, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, Dca
-----------------------------------	---	--

# ARGRPLA7R

---

	flame rating
860637445	- LC/APC Connector, Singlemode, Green
860650412	- TeraSPEED® LC UniBoot 2.0MM UPC/LC UNIBOOT CONNECTOR KIT
860661407	- MPO16,ULL,FEMALE,SM,GREEN,3mm