


# OM412D42YAE4XN4XUU00

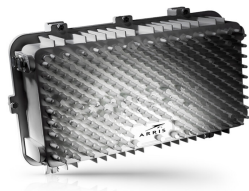

## Opti Max™ 1.2 GHz Deep OM4120 Optical Node, 4x4 HFC Segmentable

- \*Product complies with the Build America, Buy America Act (BABAA) requirements of the Infrastructure Investment and Jobs Act of 2021 (Pub. L. 117- 58, §§ 70901-70953), or is the subject of a waiver approved by the Secretary of Commerce or designee. Compliance requirements and waiver applicability vary based on government funding program. Check the laws and regulations for your specific program.

### Product Classification

Regional Availability	Asia   Australia/New Zealand   EMEA   Latin America   North America
Product Type	Optical node platform
Product Series	OM4120
Government Requirements	Build America Buy America (BABA) compliant*

### General Specifications

Location of Manufacturing	Waived per BABA waiver for BEAD Program
---------------------------	---

### Electrical Specifications

Input Voltage Range, ac	44–90 V
-------------------------	---------

### Environmental Specifications

Operating Temperature	-40 °C to +60 °C (-40 °F to +140 °F)
Relative Humidity	5%–95%, non-condensing

### Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

