

# U3V2X2XBF

## Base Product



Ultra Low Loss (ULL) LazrSPEED® 550 OM5 MPO/24 (Pinned) to MPO/24 (Pinned), Pre-terminated Cable, MPO24, 24-Fiber, LSZH

## Product Classification

<b>Regional Availability</b>	Europe   Middle East/Africa
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber trunk cable assembly
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	Not available in the United States or Canada

## General Specifications


<b>Color, connector A</b>	Lime green
<b>Color, connector B</b>	Lime green
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Lime green
<b>Interface, Connector A</b>	MPO-24/UPC Male
<b>Interface, Connector B</b>	MPO-24/UPC Male
<b>Jacket Color</b>	Lime green
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	24
<b>Total Fibers, quantity</b>	24

## Dimensions

<b>Breakout Length</b>	33 in
<b>Cable Assembly Length Range (m)</b>	3 – 305
<b>Cable Assembly Length Range (ft)</b>	10 – 999

## Ordering Tree

# U3V2X2XBF

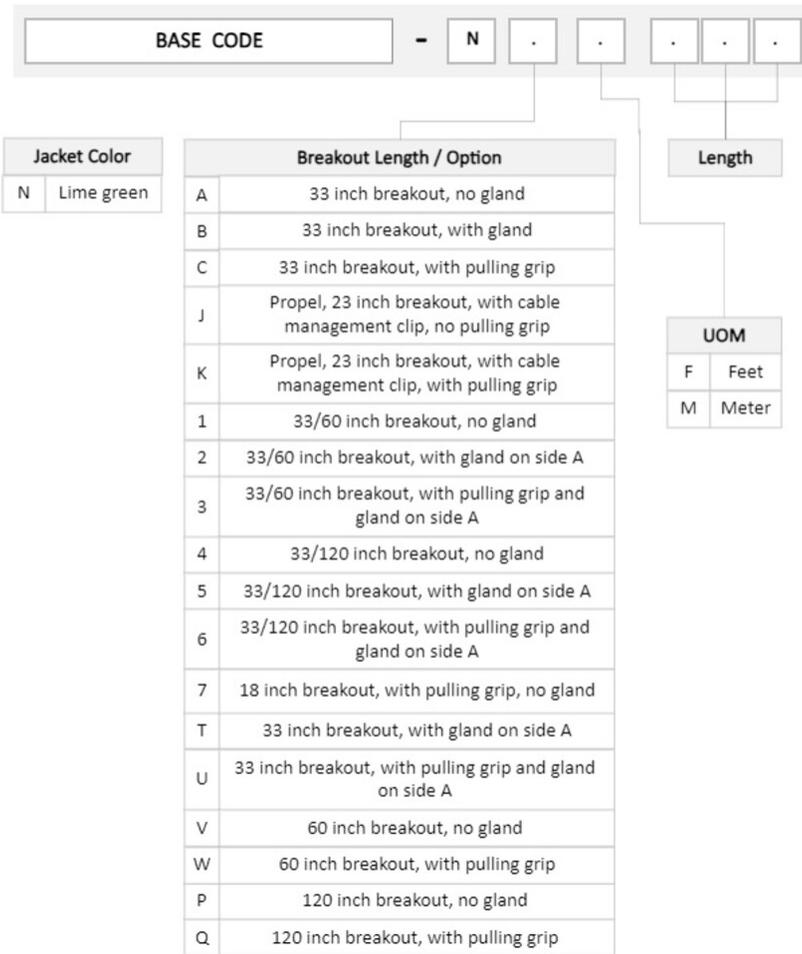

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Multimode

**Fiber Type** OM5, LazrSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Low Smoke Zero Halogen (LSZH)

## Regulatory Compliance/Certifications

# U3V2X2XBF

---

## Agency

CHINA-ROHS  
ISO 9001:2015  
REACH-SVHC  
ROHS  
UK-ROHS

## Classification

Below maximum concentration value  
Designed, manufactured and/or distributed under this quality management system  
Compliant as per SVHC revision on [www.commscope.com/ProductCompliance](http://www.commscope.com/ProductCompliance)  
Compliant  
Compliant



## Included Products

- |                                       |   |   |
|---------------------------------------|---|---|
| 760253233<br>N-024-MP-5G-F24LM/30T/B2 | - | Fiber indoor cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 24 fiber with 24-fiber, 3.0mm subunits, Gel-free, Multimode OM5, Feet jacket marking, Lime green jacket color, B2ca flame rating |
| 860662280                             | - | MPO24,MALE,OM5,LIME,3.0MM   |