


CK6451-000 | FOSC-OPGW-B4NT-O-NNN

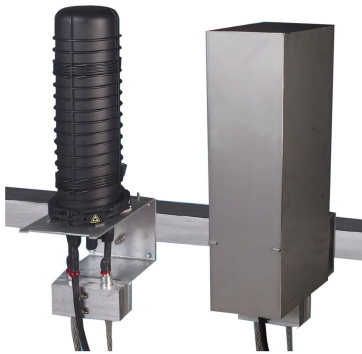

FOSC® OPGW B Fiber Optic Splice Closure, Heat Shrink Cable sealing, butt type, no pre-installed trays

Product Classification

Regional Availability	Asia EMEA Latin America North America
Product Type	Single-ended, round fiber closure
Product Brand	FOSC®
Product Series	FOSC OPGW

General Specifications

Cable Entry Drop Port Style	Round
Cable Entry Main Port Style	Round
Cable Ports Quantity, total	1 oval port (2 cables) + 4 round ports
Cable Sealing Type	Heat shrink
Closure Sealing Type	Dome-to-base clamp with O-ring
Closure Style	Single-ended
Color	Black
Mounting	Pole Strand Wall
Network Area Type	Feeder
Splice Tray Included, quantity	0
Splicing Capacity, Mass Fusion, maximum	144
Splicing Capacity, Single Fusion, maximum	96
Splicing Capacity, Single Splice, 12 fibers, maximum	96
Splicing Capacity, Single Splice, 6 fibers, maximum	48
Splicing Type, Supported	Mass fusion Single fusion

Dimensions


Height	240 mm 9.449 in
---------------	-------------------

CK6451-000 | FOSC-OPGW-B4NT-O-NNN

Width	202 mm 7.953 in
Length	715 mm 28.15 in
Main Cable Diameter, maximum	19 mm 0.748 in

Ordering Tree

FOSC - OPGW - XX XXX - X - X X X

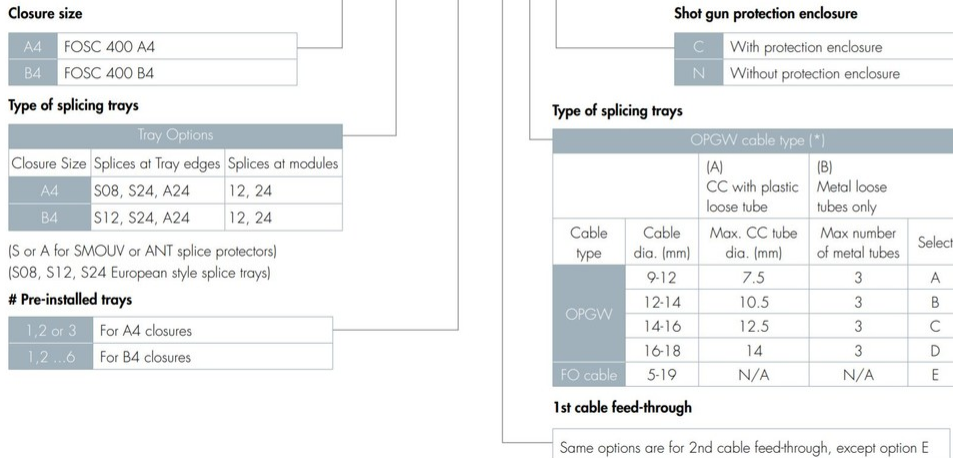

Material Specifications

Material Type	Impact-resistant polymer
----------------------	--------------------------

Environmental Specifications

Environmental Space	Above ground
Qualification Standards	IEC 61300, 6 m waterhead

Packaging and Weights

Packaging quantity	1
Packaging Type	Box Carton
Weight, net	18 kg 39.683 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance

CK6451-000 | FOSC-OPGW-B4NT-0-NNN

ROHS

Compliant

