


CZ7472-000 | FIST-GPST-12-AAD-2

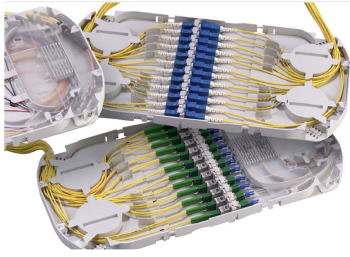

FIST GPST Fiber Patch Tray, 12 ports, FC/APC, singlemode, 19 in, gray, left /right patch cord routing

OBSOLETE

This product was discontinued on: March 1, 2018

Product Classification

Regional Availability	EMEA
Product Type	Fiber patch tray
Product Brand	FIST®
Product Series	FIST-GPST

General Specifications

Functionality	Patching
Color	Gray
Interface, front	FC/APC
Patch Cord Entry Location	Front, left side Front, right side
Patching Capacity, maximum	12
Splicing Capacity, maximum	0
Total Ports, quantity	12

Dimensions

Height	18 mm 0.709 in
Width	355 mm 13.976 in
Depth	190 mm 7.48 in

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-5 °C to +45 °C (+23 °F to +113 °F)
Storage Temperature	-30 °C to +60 °C (-22 °F to +140 °F)
Relative Humidity	Up to 93%, non-condensing

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

