

FMT-DSR020A00-S24B

FMT Fiber Termination/Storage Panel, with sliding tray, 24 FC/UPC, singlemode, 1RU, 19 in, black



OBSOLETE

This product was discontinued on: March 1, 2018

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/storage panel
Product Series	FMT

General Specifications


Functionality	Patching
Body Style	Symmetrical
Color	Black
Color, front	Black
Interface, front	FC/UPC
Rack Type	EIA 19 in EIA 23 in
Rack Units	1
Shelf Movement	Sliding
Total Ports, quantity	24

Dimensions

Height	44.45 mm 1.75 in
Width	482.6 mm 19 in
Depth	279.91 mm 11.02 in

FMT-DSR020A00-S24B

Ordering Tree

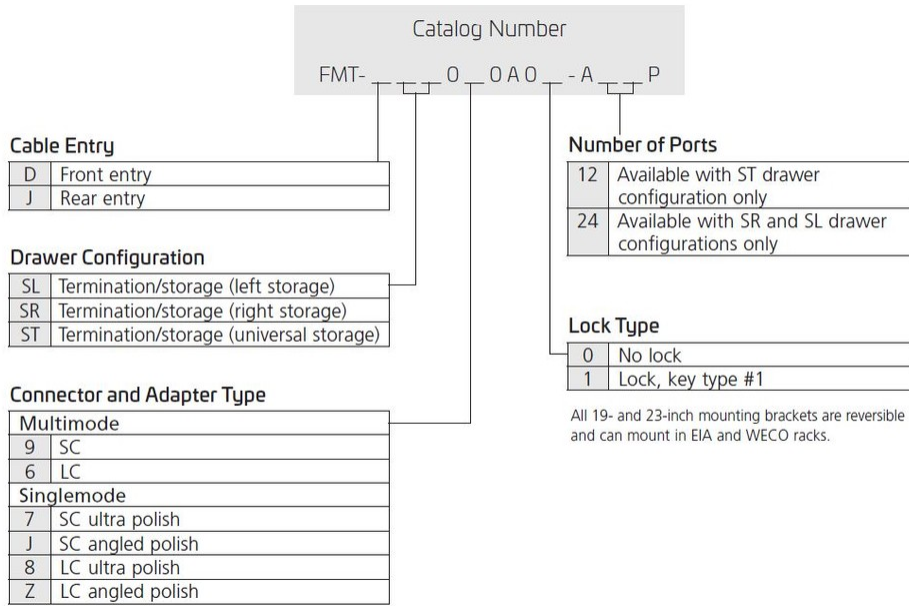

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant

