


RDT-SJ24J2PC10020

RapidFiber® FDT Distribution Terminal, 24-fiber, SC/APC, 100 ft

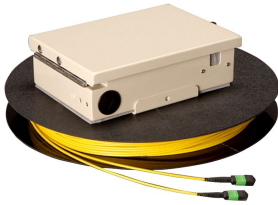

Product Classification

Regional Availability	EMEA Latin America North America
Product Type	Fiber distribution terminal
Product Brand	RapidFiber®
Product Series	FDT

General Specifications

Adapters, quantity	24
Cable Color	Yellow
Cable Entry Location	Bottom left Top left Top right
Cable Type	Indoor/outdoor - Stranded
Color	Putty white
Front Cover Type	Hinged with lock
Growth Configuration	Fully loaded
Interface	SC/APC
Interface, stub	No connector
Mounting	Wall
Port, quantity	24

Dimensions

Height	152.4 mm 6 in
Width	228.6 mm 9 in
Depth	101.6 mm 4 in
Cable Length	30.48 m 100 ft

RDT-SJ24J2PC10020

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Environmental Space Indoor

Qualification Standards NEMA, Type 12

Packaging and Weights

Included Grommets

Packaging quantity 1