


RDT-SJ24J2PC2002A

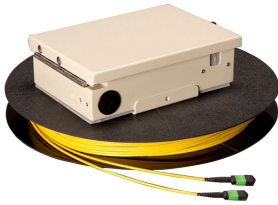

RapidFiber® FDT Distribution Terminal, 24-fiber, SC/APC, MPO at far end, 200 ft

Product Classification

Regional Availability	EMEA Latin America North America
Product Type	Fiber distribution terminal
Product Brand	RapidFiber®
Product Series	FDT

General Specifications

Adapters, quantity	24
Cable Color	Yellow
Cable Entry Location	Bottom left Top left Top right
Cable Type	Indoor/outdoor - Stranded
Color	Putty white
Front Cover Type	Hinged with lock
Growth Configuration	Fully loaded
Interface	SC/APC
Interface, stub	MPO
Mounting	Wall
Port, quantity	24

Dimensions

Height	152.4 mm 6 in
Width	228.6 mm 9 in
Depth	101.6 mm 4 in
Cable Length	60.96 m 200 ft

RDT-SJ24J2PC2002A

Material Specifications

Finish Powder coated

Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Environmental Space Indoor

Qualification Standards NEMA, Type 12

Packaging and Weights

Included Grommets

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

