


# 760201194 | 360-iP-MFTP-E-1U-BLANK

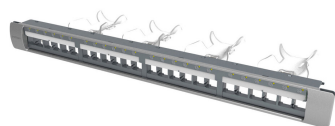

SYSTIMAX 360™ iPatch® FTP Evolve Modular Panel, 24 port without jacks

## Product Classification

### Regional Availability

Asia | Australia/New Zealand | EMEA | Latin America | North America

### Portfolio

SYSTIMAX®

### Product Type

RJ45 patch panel

### Product Brand

SYSTIMAX 360™ | iPatch®

## General Specifications

### ANSI/TIA Category

6A

### Cable Type

Shielded

### Color

Silver

### Intelligence Type

iPatch® enabled

### Panel Style

Straight

### Rack Units

1

### Total Ports, quantity

24

### Wiring

T568A | T568B

## Dimensions

### Height

44.45 mm | 1.75 in

### Width

482.6 mm | 19 in

### Depth

206.5 mm | 8.13 in

### Compatible Diameter Over Dielectric, maximum

1.168 mm | 0.046 in

## Electrical Specifications

### Current Rating at Temperature

1.5 A @ 20 °C | 1.5 A @ 68 °F

### Dielectric Withstand Voltage, RMS, conductive surface

1,500 Vac @ 60 Hz

### Insulation Resistance, minimum

500 MOhm

## Mechanical Specifications

**Plug Insertion Life, minimum** 750 times

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Storage Temperature** -40 °C to +70 °C (-40 °F to +158 °F)

**Safety Standard** UL | cUL

## Packaging and Weights

**Packaging quantity** 1

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted

