


# 760238001 | EHD12-DM-24LA-SM-AS-LL

EHD LL Singlemode MPO-12 distribution module, 24LC to 2x12f MPOs pinned, dust plugs

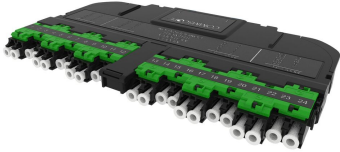

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   EMEA   Latin America   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Fiber module
<b>Product Series</b>	EHD

## General Specifications

<b>Functionality</b>	Breakout
<b>Color, front</b>	Green
<b>Color, rear</b>	Black
<b>Interface, front</b>	LC/APC
<b>Interface, rear</b>	MPO
<b>Interface Feature, rear</b>	Key up/down   Pinned
<b>Polarity</b>	Method A   Pairs, straight
<b>Shuttered</b>	No
<b>Total Fibers, quantity</b>	24

## Dimensions

<b>Height</b>	12.45 mm   0.49 in
<b>Width</b>	169.67 mm   6.68 in
<b>Depth</b>	115.32 mm   4.54 in

## Optical Specifications

<b>Fiber Mode</b>	Singlemode
<b>Fiber Type</b>	OS2

# 760238001 | EHD12-DM-24LA-SM-AS-LL

---

**Insertion Loss, maximum** 0.75 dB

## Environmental Specifications

**Qualification Standards** IEC 61753-1 | TIA-568.3-D

**Safety Standard** CE | CSA | UL

## Packaging and Weights

**Packaging quantity** 1

**Weight, net** 0.136 kg | 0.3 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

