

760036457 | MODG2-6SCA-SM-PT-B

G2 Modular Cassette with 6 SC APC TeraSPEED® Singlemode Pigtails, Type B

OBSOLETE

Replaced By:

760109587

360G2 Cartridge 6-SCA-SM-GR-PIGTAILS B

360G2 Singlemode Fiber Cassette 6 SC APC with pigtails B

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	SYSTIMAX®
Product Type	Fiber cassette with pigtails
Product Brand	TeraSPEED®

General Specifications

Adapter Color	Green
Interface, front	SC/APC
Interface, rear	Stranded pigtail
Total Fibers, quantity	6
Total Ports, quantity, front	6

Dimensions

Height	30.48 mm 1.2 in
Width	91.44 mm 3.6 in
Depth	119.38 mm 4.7 in
Pigtail Length	1.5 m 4.921 ft

Optical Specifications

Fiber Type	G.652.D and G.657.A1, TeraSPEED® OS2
Insertion Loss, typical	0.4 dB
Return Loss, minimum	65 dB

Environmental Specifications

760036457 | MODG2-6SCA-SM-PT-B

Safety Standard UL

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

ISO 9001:2015

Classification

Designed, manufactured and/or distributed under this quality management system



Included Products

- 760061374 AFA-SC06-GR-SHUTTERED – TeraSPEED® SC-APC Multiport Shuttered Adapter, Green, Single Pack
- 860312933 – TeraSPEED® SC APC 0.9 mm Pigtail, red, 1.5 m
- 860312941 – TeraSPEED® SC APC 0.9 mm Pigtail, black, 1.5 m
- 860312958 – TeraSPEED® SC APC 0.9 mm Pigtail, yellow, 1.5 m
- 860312966 – TeraSPEED® SC APC 0.9 mm Pigtail, violet, 1.5 m
- 860312974 – TeraSPEED® SC APC 0.9 mm Pigtail, rose, 1.5 m
- 860312982 – TeraSPEED® SC APC 0.9 mm Pigtail, aqua, 1.5 m

760061374 | AFA-SC06-GR-SHUTTERED



TeraSPEED® SC-APC Multiport Shuttered Adapter, Green, Single Pack

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber adapter
Product Brand	TeraSPEED®
Product Series	AFA

General Specifications

Body Style	Ganged
Color	Green
Interface	SC/APC
Mounting	No flange
Shuttered	Yes
Total Ports, quantity	6

Material Specifications

Alignment Sleeve Material	Zirconia
----------------------------------	----------

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Packaging and Weights

Packaging quantity	1
---------------------------	---

Regulatory Compliance/Certifications


Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant

760061374 | AFA-SC06-GR-SHUTTERED

UK-ROHS

Compliant



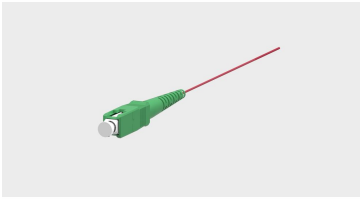

TeraSPEED® SC APC 0.9 mm Pigtail, red, 1.5 m

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Red
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0° 1.00 lb @ 90°
--	------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1, TeraSPEED® OS2
-------------------	--

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312933





TeraSPEED® SC APC 0.9 mm Pigtail, black, 1.5 m

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Black
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0° 1.00 lb @ 90°
--	------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1, TeraSPEED® OS2
-------------------	--

Environmental Specifications


Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312941



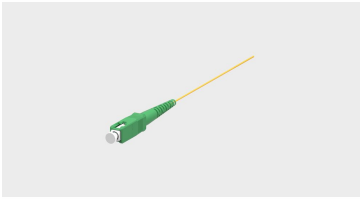

TeraSPEED® SC APC 0.9 mm Pigtail, yellow, 1.5 m

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Yellow
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1, TeraSPEED® OS2
-------------------	--

Environmental Specifications


Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312958



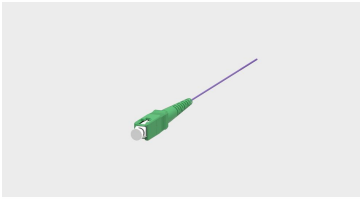

TeraSPEED® SC APC 0.9 mm Pigtail, violet, 1.5 m

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Violet
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1, TeraSPEED® OS2
-------------------	--

Environmental Specifications


Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312966



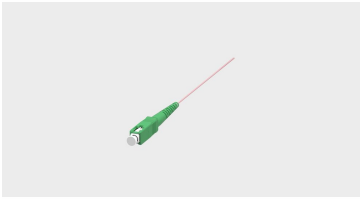

TeraSPEED® SC APC 0.9 mm Pigtail, rose, 1.5 m

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Rose
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1, TeraSPEED® OS2
-------------------	--

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312974





TeraSPEED® SC APC 0.9 mm Pigtail, aqua, 1.5 m

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber pigtail, unjacketed
Product Brand	TeraSPEED®

General Specifications

Construction Type	Pigtail, jacketed
Interface, Connector A	SC/APC
Jacket Color	Aqua
Total Fibers, quantity	1

Mechanical Specifications

Cable Retention Strength, maximum	1.00 lb @ 0 ° 1.00 lb @ 90 °
--	--------------------------------

Optical Specifications

Fiber Type	G.652.D and G.657.A1, TeraSPEED® OS2
-------------------	--

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Plenum

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system

860312982

