


760065888 | MODG2-12LCA-SM-PT

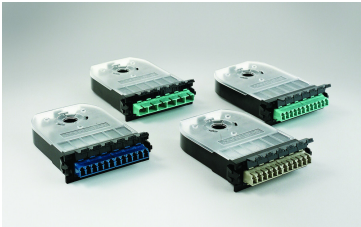

G2 Modular Cassette with 12 LC APC TeraSPEED® Singlemode Pigtails

OBSOLETE

Replaced By:

760109504
360G2 Cartridge 12-LCA-SM-GR-PIGTAILS 360G2 Singlemode Fiber Cassette 12 LC APC, with pigtails, iPatch Ready

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	SYSTIMAX®
Product Type	Fiber cassette with pigtails
Product Brand	TeraSPEED®

General Specifications

Adapter Color	Green
Interface, front	LC/APC
Interface, rear	Stranded pigtail
Total Fibers, quantity	12
Total Ports, quantity, front	12

Dimensions

Height	30.48 mm 1.2 in
Width	91.44 mm 3.6 in
Depth	119.38 mm 4.7 in
Pigtail Length	1.5 m 4.921 ft

Optical Specifications

Fiber Type	G.652.D and G.657.A1, TeraSPEED® OS2
Insertion Loss, typical	0.4 dB
Return Loss, minimum	65 dB

Environmental Specifications

Safety StandardUL

Packaging and Weights

Packaging quantity1

Regulatory Compliance/Certifications

Agency	Classification
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system



Included Products

760066639 AFA-LC12-GR-10-BULK-PACK-SHUTTERED	–	TeraSPEED® LC-APC Multiport Shuttered Adapter, Green, 10 Bulk Pack
860387844	–	TeraSPEED® LC APC 0.9 mm Pigtail, blue, 1.5 m
860387851	–	TeraSPEED® LC APC 0.9 mm Pigtail, orange, 1.5 m
860387869	–	TeraSPEED® LC APC 0.9 mm Pigtail, green, 1.5 m
860387877	–	TeraSPEED® LC APC 0.9 mm Pigtail, brown, 1.5 m
860387885	–	TeraSPEED® LC APC 0.9 mm Pigtail, slate, 1.5 m
860387893	–	TeraSPEED® LC APC 0.9 mm Pigtail, white, 1.5 m
860387901	–	TeraSPEED® LC APC 0.9 mm Pigtail, red, 1.5 m
860387919	–	TeraSPEED® LC APC 0.9 mm Pigtail, black, 1.5 m
860387927	–	TeraSPEED® LC APC 0.9 mm Pigtail, yellow, 1.5 m
860387935	–	TeraSPEED® LC APC 0.9 mm Pigtail, violet, 1.5 m
860387943	–	TeraSPEED® LC APC 0.9 mm Pigtail, rose, 1.5 m
860387950	–	TeraSPEED® LC APC 0.9 mm Pigtail, aqua, 1.5 m