

CZ6065-000 | FL2-C480072KN-4C52

FL2000 Fiber Termination/Splice Panel, pre-terminated with pigtails, 72 LC/UPC, singlemode, 5RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FL2000

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	6
Cable Exit Location	Rear, left side Rear, right side
Color	Putty white
Color, front	Putty white
Growth Configuration	Fully loaded
Interface, front	LC
Interface Feature, front	Standard
Patching Capacity, maximum	72
Rack Type	EIA 19 in
Rack Units	5
Shelf Movement	Hinged
Splicing Capacity, maximum	72
Total Ports, quantity	72

Dimensions

Height	222.25 mm 8.75 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Ordering Tree

CZ6065-000 | FL2-C480072KN-4C52

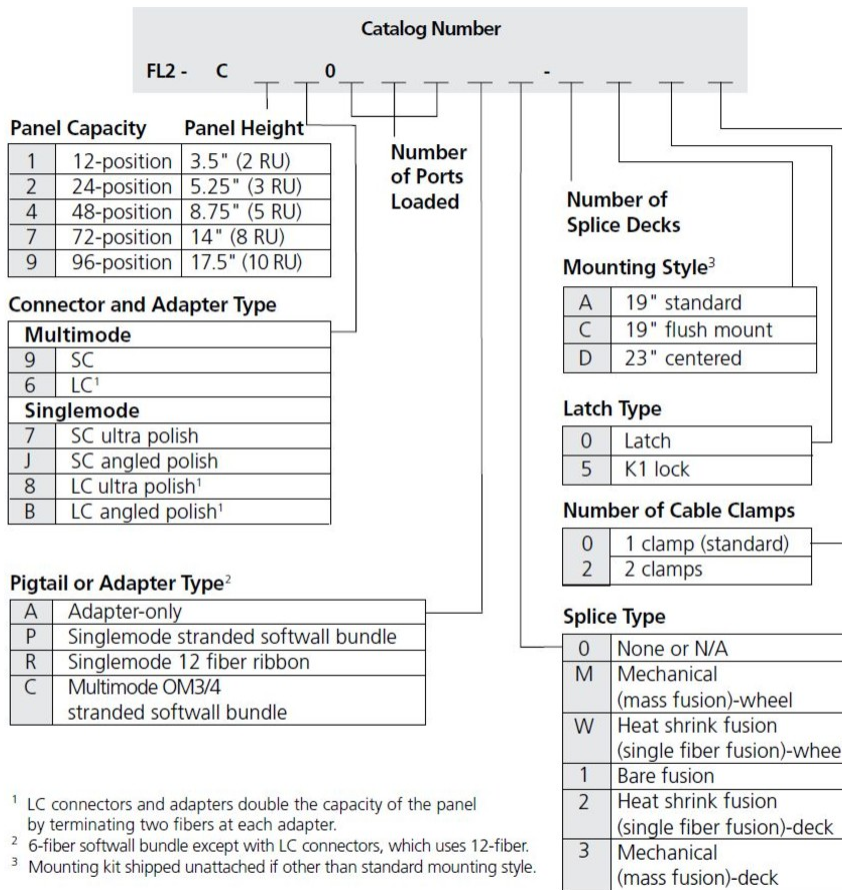

Material Specifications

Finish Powder coated
Material Type Steel

Optical Specifications

Fiber Mode Singlemode

Environmental Specifications

Operating Temperature -40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature -40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included Mounting hardware
Packaging quantity 1

Regulatory Compliance/Certifications

Agency

CHINA-ROHS

REACH-SVHC

ROHS

Classification

Below maximum concentration value

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

Compliant

