


# FDP-G2KS27072-TM

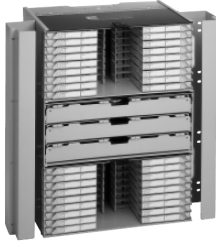

CMT Fiber Termination/Splice Panel, 72, FC/UPC, pre-terminated with pigtailed, singlemode, 13RU, 19 in, putty white

## OBSOLETE

This product was discontinued on: March 1, 2018

## Product Classification

|                              |                               |
|------------------------------|-------------------------------|
| <b>Regional Availability</b> | Latin America   North America |
| <b>Portfolio</b>             | CommScope®                    |
| <b>Product Type</b>          | Fiber patch/splice panel      |
| <b>Product Series</b>        | CMT                           |

## General Specifications

|                                  |                                      |
|----------------------------------|--------------------------------------|
| <b>Functionality</b>             | Patching   Splicing                  |
| <b>Body Style</b>                | Symmetrical                          |
| <b>Color</b>                     | Putty white                          |
| <b>Color, front</b>              | Putty white                          |
| <b>Interface, front</b>          | FC/UPC                               |
| <b>Patch Cord Entry Location</b> | Front, left side   Front, right side |
| <b>Rack Type</b>                 | EIA 19 in   EIA 23 in                |
| <b>Rack Units</b>                | 13                                   |
| <b>Total Ports, quantity</b>     | 72                                   |

## Dimensions

|               |                      |
|---------------|----------------------|
| <b>Height</b> | 577.85 mm   22.75 in |
| <b>Width</b>  | 482.6 mm   19 in     |
| <b>Depth</b>  | 304.8 mm   12 in     |

## Material Specifications

|               |               |
|---------------|---------------|
| <b>Finish</b> | Powder coated |
|---------------|---------------|

# FDP-G2KS27072-TM

---

**Material Type** Steel

## Optical Specifications

**Fiber Mode** Singlemode

## Packaging and Weights

**Included** Mounting hardware

**Packaging quantity** 1

## Regulatory Compliance/Certifications

| <b>Agency</b> | <b>Classification</b>  |
|---------------|--|
| CHINA-ROHS    | Above maximum concentration value  |
| REACH-SVHC    | Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a> |
| ROHS          | Compliant/Exempted   |
| UK-ROHS       | Compliant  |

