


FL2-96RPNL

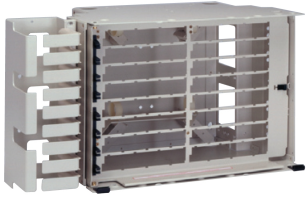

FL2000 Fiber Termination Panel, unloaded, 96 Ports, 6RU, 19 in, putty white

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch panel
Product Series	FL2000

General Specifications

Functionality	Patching
Color	Putty white
Color, front	Putty white
Growth Configuration	Unloaded
Interface, front	Unloaded
Patching Capacity, maximum	96
Rack Type	EIA 19 in
Rack Units	6
Shelf Movement	Hinged
Splicing Capacity, maximum	0
Total Ports, quantity	96

Dimensions

Height	266.7 mm 10.5 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Material Specifications

Finish	Powder coated
Material Type	Steel

FL2-96RPNL

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant/Exempted

