

FL2-C220024KW-2D00

FL2000 Fiber Termination/Splice Panel, pre-terminated with pigtails, 24 FC/UPC, singlemode, 3RU, 23 in, putty white

OBSOLETE

This product was discontinued on: March 1, 2018

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FL2000

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	4
Cable Exit Location	Rear, left side Rear, right side
Color	Putty white
Color, front	Putty white
Growth Configuration	Fully loaded
Interface, front	FC/UPC
Patching Capacity, maximum	24
Rack Type	EIA 23 in
Rack Units	3
Shelf Movement	Hinged
Splicing Capacity, maximum	24
Total Ports, quantity	24

Dimensions

Height	133.35 mm 5.25 in
Width	584.2 mm 23 in
Depth	256.54 mm 10.1 in

FL2-C220024KW-2D00

Ordering Tree

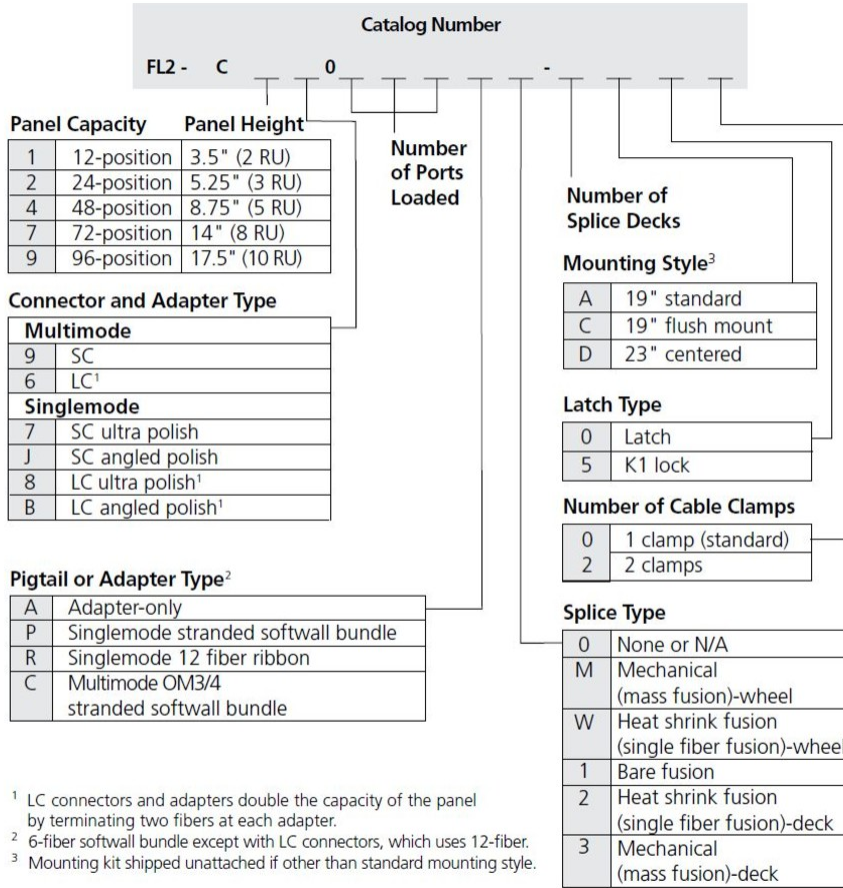

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

FL2-C220024KW-2D00

Included Mounting hardware

Packaging quantity 1

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Above maximum concentration value

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant/Exempted

UK-ROHS

Compliant/Exempted

