

FL2-CA80012PN-1C00



FL2000 Fiber Termination/Splice Panel, pre-terminated with pigtails, 12 LC/UPC, singlemode, 2RU, 19 in, black

Product Classification

Regional Availability	Latin America North America
Portfolio	CommScope®
Product Type	Fiber patch/splice panel
Product Series	FL2000

General Specifications


Functionality	Patching Splicing
Adapter Packs Included, quantity	1
Cable Exit Location	Rear, left side Rear, right side
Color	Black
Growth Configuration	Partially loaded
Interface, front	LC/UPC
Rack Type	EIA 19 in
Rack Units	2
Shelf Movement	Hinged
Splicing Capacity, maximum	24
Total Ports, quantity	12

Dimensions

Height	88.9 mm 3.5 in
Width	482.6 mm 19 in
Depth	256.54 mm 10.1 in

Ordering Tree

FL2-CA80012PN-1C00

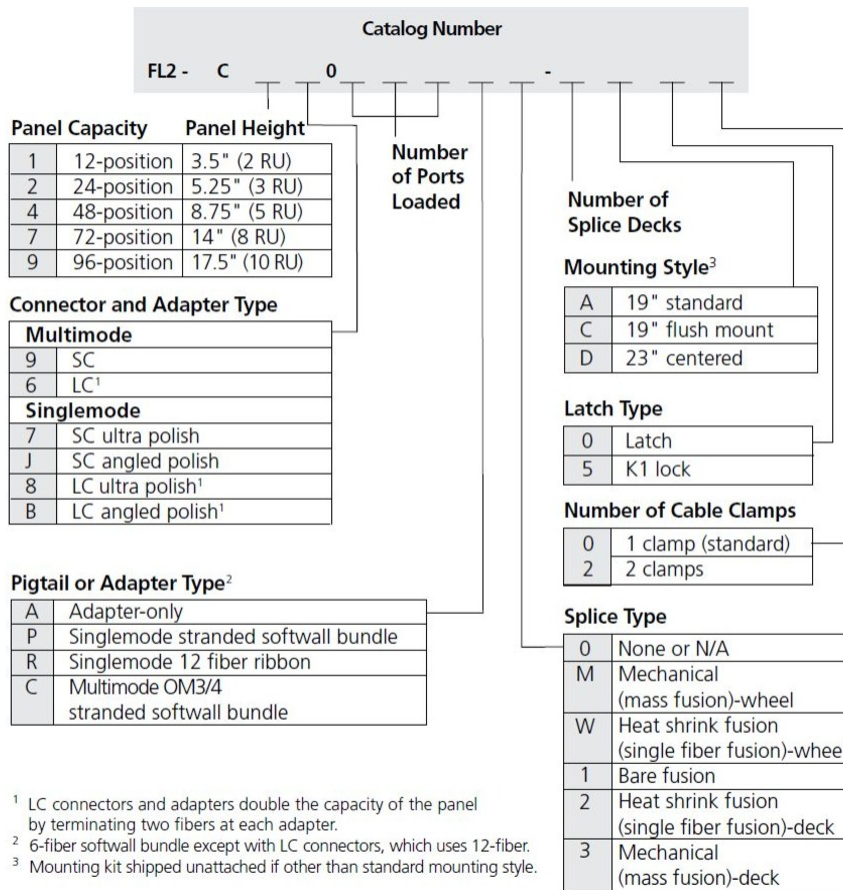

Material Specifications

Finish	Powder coated
Material Type	Steel

Optical Specifications

Fiber Mode	Singlemode
-------------------	------------

Environmental Specifications

Operating Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Storage Temperature	-40 °C to +85 °C (-40 °F to +185 °F)

Packaging and Weights

Included	Mounting hardware
Packaging quantity	1

FL2-CA80012PN-1C00

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant/Exempted

